


Outside Micrometer Economy Design

Item number: 103-165

Images

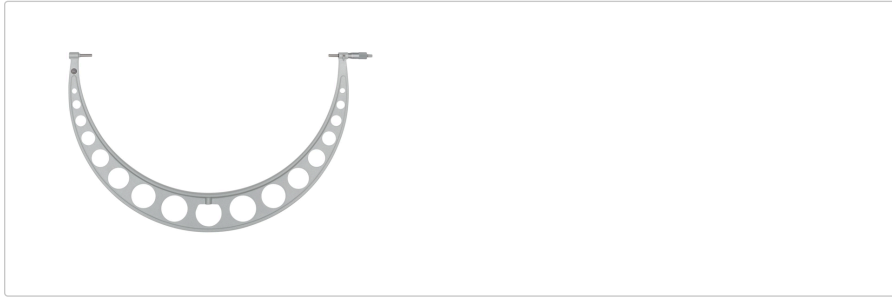

Description


Lightweight workshop design with baked-enamel-finished frame.

- Equipped with Ratchet Stop for constant measuring force.

Features

Model:	OM-725
Digital/Analog:	Analog
Delivered:	Including box, key, setting standard
Inch-Metric:	Metric
Range:	700-725 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	±9 μm
Flatness:	1 μm
Parallelism:	9 μm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm (≤300 mm) ø 8 mm (>300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø21 mm
Measuring force:	10 - 15 N
Mass:	5835 g

Dimensions

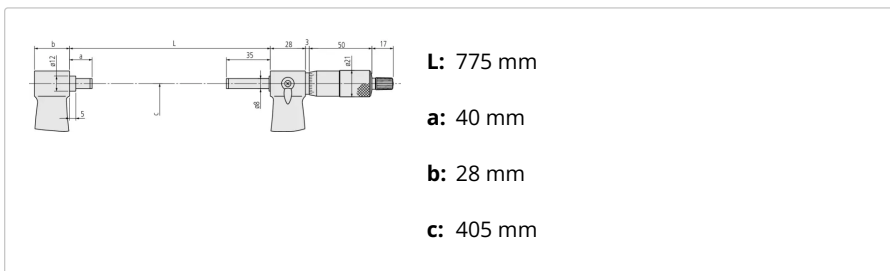

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: 1,183.00 €*

Standard accessories:

Micrometer Setting Standard

Length: 700mm

Art No. 167-128

Suggested retail price: 261.00 €*

