


Outside Micrometer Economy Design

Item number: 103-166

Images

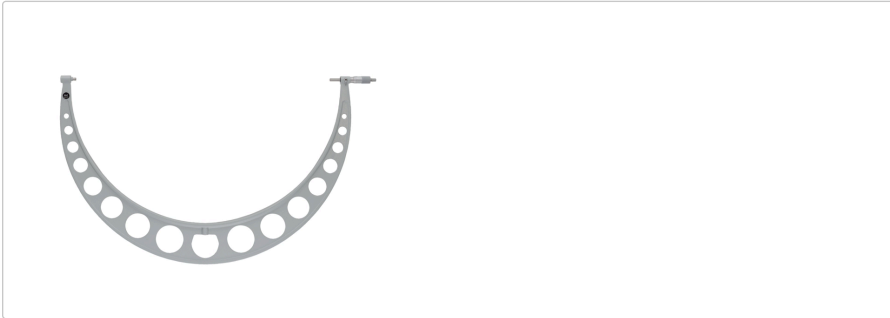

Description

- Lightweight workshop design with baked-enamel-finished frame.
- Equipped with Ratchet Stop for constant measuring force.

Features

Model:	OM-750
Digital/Analog:	Analog
Delivered:	Including box, key, setting standard
Inch-Metric:	Metric
Range:	725-750 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	$\pm 9 \mu\text{m}$
Flatness:	$1 \mu\text{m}$
Parallelism:	$9 \mu\text{m}$
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35 \text{ mm}$ ($\leq 300 \text{ mm}$) $\varnothing 8 \text{ mm}$ ($> 300 \text{ mm}$) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21 \text{ mm}$
Measuring force:	10 - 15 N
Mass:	5860 g

Dimensions

L: 775 mm
a: 15 mm
b: 28 mm
c: 405 mm

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: 1,183.00 €*

Standard accessories:

Micrometer Setting Standard

Length: 725mm

Art No. 167-129

Suggested retail price: 272.00 €*

