


# Outside Micrometer Economy Design

Item number: 103-167

## Images

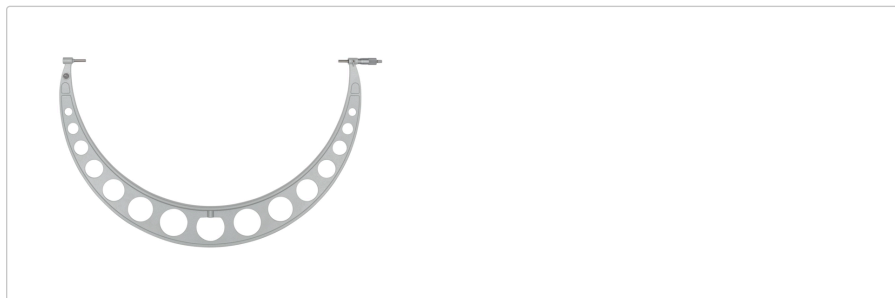

## Description


Lightweight workshop design with baked-enamel-finished frame.

- Equipped with Ratchet Stop for constant measuring force.

## Features

<b>Model:</b>	OM-775
<b>Digital/Analog:</b>	Analog
<b>Delivered:</b>	Including box, key, setting standard
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	750-775 mm
<b>Graduation:</b>	0,01 mm
<b>Max. Permissible Error J MPE:</b>	$\pm 9 \mu\text{m}$
<b>Flatness:</b>	$1 \mu\text{m}$
<b>Parallelism:</b>	$9 \mu\text{m}$
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring spindle:</b>	With spindle lock, $\varnothing 6,35 \text{ mm}$ ( $\leq 300 \text{ mm}$ ) $\varnothing 8 \text{ mm}$ ( $> 300 \text{ mm}$ ) , spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing 21 \text{ mm}$
<b>Measuring force:</b>	10 - 15 N
<b>Mass:</b>	6385 g

## Dimensions

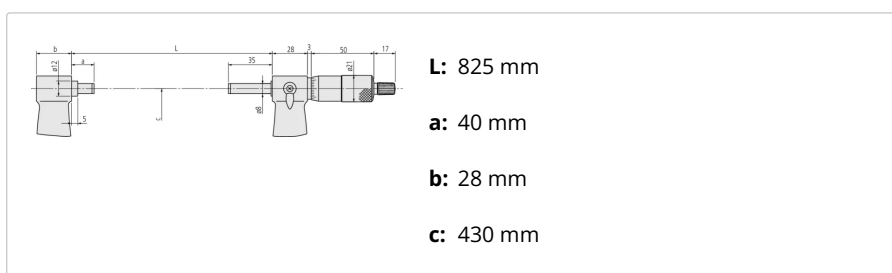

## Accessories

Optional accessories:



## Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: 1,183.00 €\*  

---

Standard accessories:

---

## Micrometer Setting Standard

Length: 750mm

Art No. 167-130

Suggested retail price: 278.00 €\*  

---

