


Outside Micrometer Economy Design

Item number: 103-170

Images

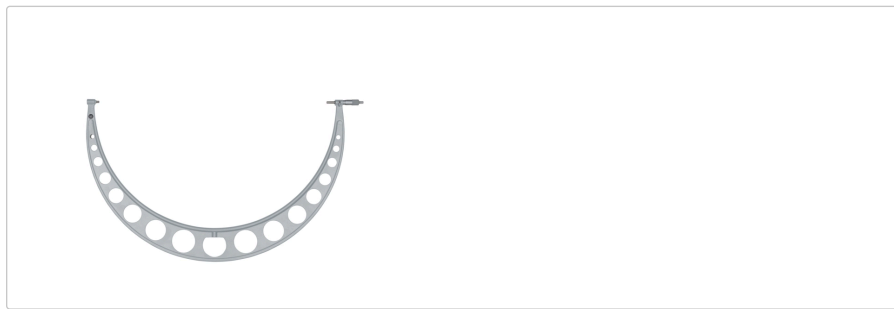

Description


Lightweight workshop design with baked-enamel-finished frame.

- Equipped with Ratchet Stop for constant measuring force.

Features

Model:	OM-850
Digital/Analog:	Analog
Delivered:	Including box, key, setting standard
Inch-Metric:	Metric
Range:	825-850 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	$\pm 9 \mu\text{m}$
Flatness:	1 μm
Parallelism:	10 μm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35 \text{ mm}$ ($\leq 300 \text{ mm}$) $\varnothing 8 \text{ mm}$ ($> 300 \text{ mm}$) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21 \text{ mm}$
Measuring force:	10 - 15 N
Mass:	6940 g

Dimensions

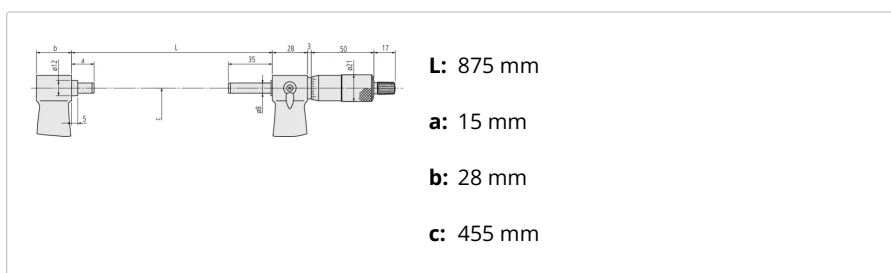

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: 1,183.00 €*

Standard accessories:

Micrometer Setting Standard

Length: 825mm

Art No. 167-133

Suggested retail price: 324.00 €*

