


Outside Micrometer Economy Design

Item number: 103-171

Images

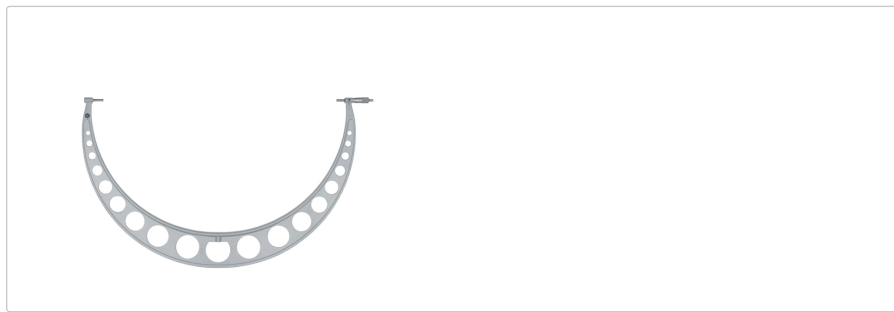

Description


Lightweight workshop design with baked-enamel-finished frame.

- Equipped with Ratchet Stop for constant measuring force.

Features

| | |
|--------------------------------------|---|
| Model: | OM-875 |
| Digital/Analog: | Analog |
| Delivered: | Including box, key, setting standard |
| Inch-Metric: | Metric |
| Range: | 850-875 mm |
| Graduation: | 0,01 mm |
| Max. Permissible Error J MPE: | ±9 μm |
| Flatness: | 1 μm |
| Parallelism: | 10 μm |
| Measuring face: | Carbide-tipped, micro-lap finish |
| Measuring spindle: | With spindle lock, ø6,35 mm (≤300 mm) ø 8 mm (>300 mm) , spindle pitch 0,5 mm |
| Scale: | Thimble and sleeve satin chrome finish, ø21 mm |
| Measuring force: | 10 - 15 N |
| Mass: | 7565 g |

Dimensions

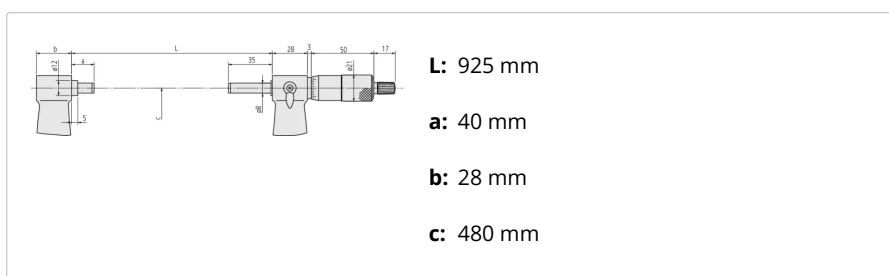

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: 1,183.00 €*

Standard accessories:

Micrometer Setting Standard

Length: 850mm

Art No. 167-134

Suggested retail price: 350.00 €*

