


Outside Micrometer Economy Design

Item number: 103-173

Images

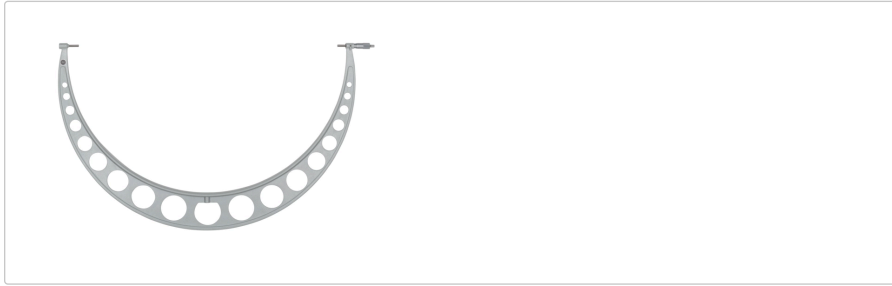

Description


Lightweight workshop design with baked-enamel-finished frame.

- Equipped with Ratchet Stop for constant measuring force.

Features

Model:	OM-925
Digital/Analog:	Analog
Delivered:	Including box, key, setting standard
Inch-Metric:	Metric
Range:	900-925 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	$\pm 9 \mu\text{m}$
Flatness:	$1 \mu\text{m}$
Parallelism:	$11 \mu\text{m}$
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35 \text{ mm}$ ($\leq 300 \text{ mm}$) $\varnothing 8 \text{ mm}$ ($> 300 \text{ mm}$) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21 \text{ mm}$
Measuring force:	10 - 15 N
Mass:	8215 g

Dimensions

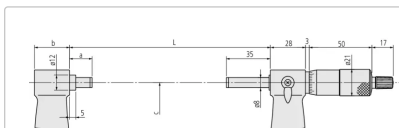

L: 975 mm

a: 40 mm

b: 28 mm

c: 505 mm

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: 1,183.00 €*

Standard accessories:

Micrometer Setting Standard

Length: 900mm

Art No. 167-136

Suggested retail price: 380.00 €*

