


Outside Micrometer Economy Design

Item number: 103-179

Images

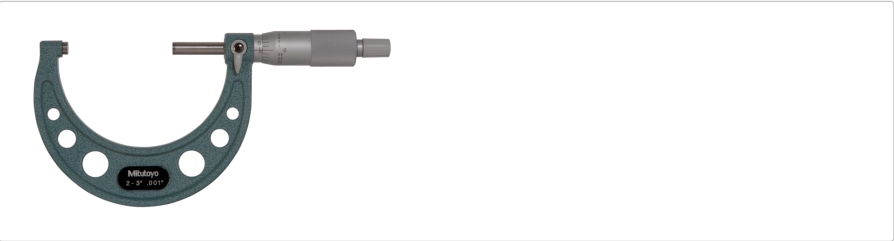


Description

A Mitutoyo basic, cost effective, non-digital micrometer with a ratchet stop to guarantee repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	2 - 3 "
Graduation:	0,001"
Max. Permissible Error J MPE:	±0.0001"
Delivered:	Including box, key, setting standard
Flatness:	0,000024"
Parallelism:	0.00008"
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Measuring force:	5 - 10 N
Mass:	315 g

Dimensions

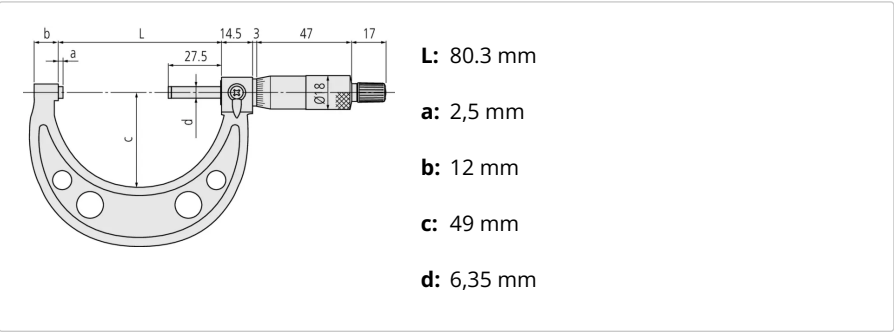

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*
~~58.00 €~~

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €*
~~70.00 €~~**

Suggested retail price: 70.00 €*
~~70.00 €~~

Standard accessories:



Micrometer Setting Standard

Length: 2"

Art No. 167-142

Suggested retail price: 36.00 €*
~~36.00 €~~