

Outside Micrometer Economy Design

Item number: 103-180

Images




Description

A Mitutoyo basic, cost effective, non-digital micrometer with a ratchet stop to guarantee repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	3 - 4 "
Graduation:	0,001"
Max. Permissible Error J MPE:	±0.00015"
Delivered:	Including box, key, setting standard
Flatness:	0,000024"
Parallelism:	0.00012"
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Measuring force:	5 - 10 N
Mass:	375 g

Dimensions

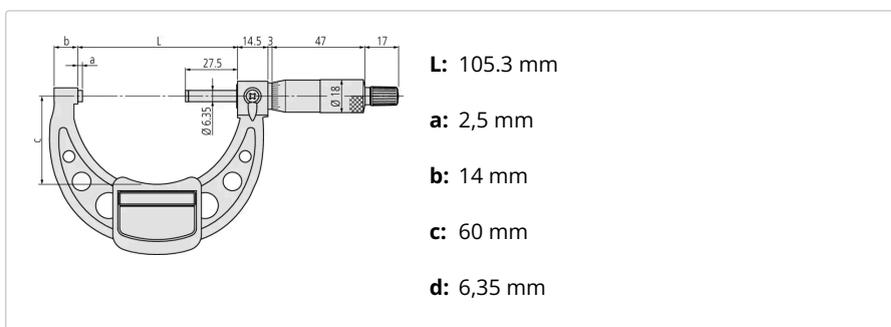

Accessories

Optional accessories:

