

Outside Micrometer Economy Design

Item number: 103-190

Images



Description


Lightweight workshop design with baked-enamel-finished frame.

- Equipped with Ratchet Stop for constant measuring force.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	13 - 14 "
Graduation:	0,001"
Max. Permissible Error J MPE:	±0.0003"
Delivered:	Including box, key, setting standard
Flatness:	0,00004"
Parallelism:	0.0002"
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
Measuring force:	10 - 15 N
Mass:	2155 g

Dimensions

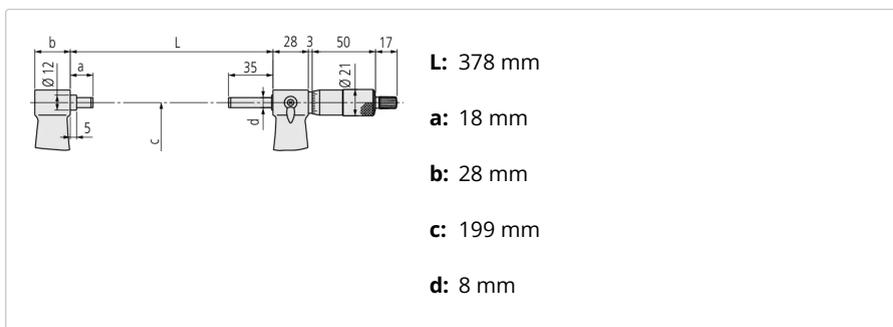

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: 1,302.00 €*

Standard accessories:

Micrometer Setting Standard

Length: 13"

Art No. 167-153

Suggested retail price: 81.00 €*

