


Outside Micrometer Economy Design

Item number: 103-192

Images

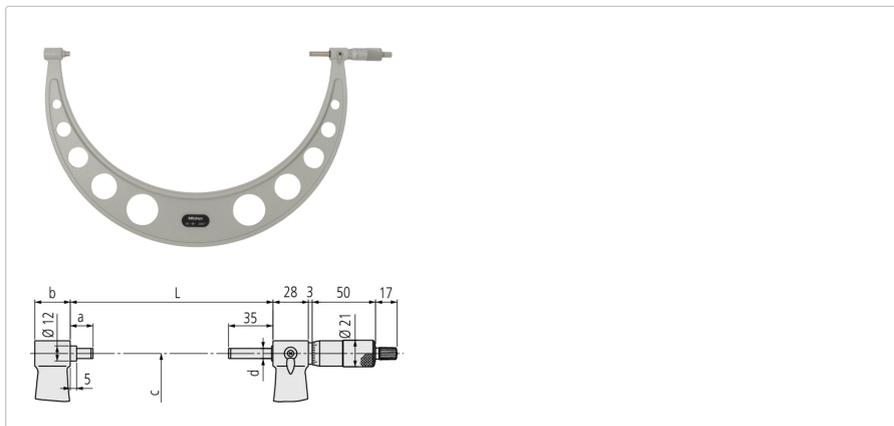

Description

A Mitutoyo basic, cost effective, non-digital micrometer with a ratchet stop to guarantee repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	15 - 16 "
Graduation:	0,001"
Max. Permissible Error J MPE:	±0,00035"
Delivered:	Including box, key, setting standard
Flatness:	0,00004"
Parallelism:	0.00024"
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm (≤300 mm) ø 8 mm (>300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø21 mm
Measuring force:	10 - 15 N
Mass:	2455 g

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: 1,302.00 €*
*MSRP

Standard accessories:

Micrometer Setting Standard

Length: 15"

Art No. 167-155

Suggested retail price: 101.00 €*
*MSRP

