

Outside Micrometer Economy Design

Item number: 103-193

Images




Description

A Mitutoyo basic, cost effective, non-digital micrometer with a ratchet stop to guarantee repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	16 - 17 "
Graduation:	0,001"
Max. Permissible Error J MPE:	±0,00035"
Delivered:	Including box, key, setting standard
Flatness:	0,00004"
Parallelism:	0.00024"
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
Measuring force:	10 - 15 N
Mass:	2715 g

Dimensions

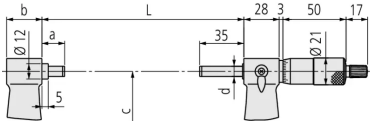

L: 453 mm

a: 18 mm

b: 28 mm

c: 236 mm

d: 8 mm

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: **1,302.00 €***

Standard accessories:



Micrometer Setting Standard

Length: 16"

Art No. 167-156

Suggested retail price: **114.00 €***