


Outside Micrometer Economy Design

Item number: 103-202

Images

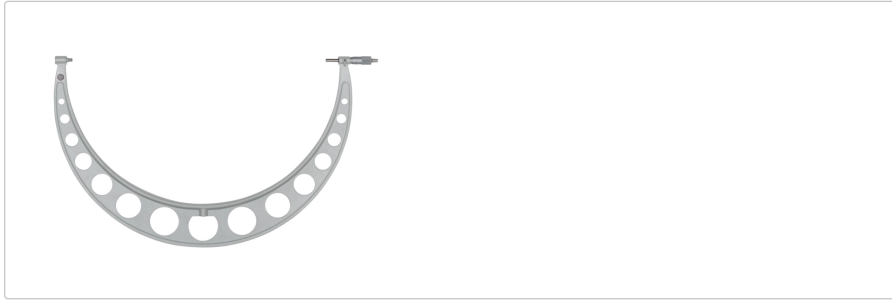

Description

Lightweight workshop design with baked-enamel-finished frame.

- Equipped with Ratchet Stop for constant measuring force.

Features

Digital/Analog:	Analog
Delivered:	Including box, key, setting standard
Inch-Metric:	Inch
Range:	25 - 26 "
Graduation:	0,001"
Max. Permissible Error J MPE:	±0.0005"
Flatness:	0,00004"
Parallelism:	0.00032"
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
Measuring force:	10 - 15 N
Mass:	4930 g

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: **1,183.00 €***

Standard accessories:

Micrometer Setting Standard

Length: 25"

Art No. 167-165

Suggested retail price: 222.00 €*

