


Outside Micrometer Economy Design

Item number: 103-210

Images

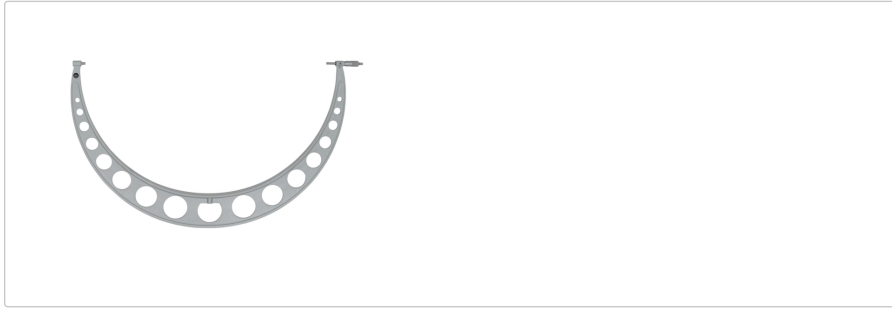

Description

Lightweight workshop design with baked-enamel-finished frame.

- Equipped with Ratchet Stop for constant measuring force.

Features

Digital/Analog:	Analog
Delivered:	Including box, key, setting standard
Inch-Metric:	Inch
Range:	33 - 34 "
Graduation:	0,001"
Max. Permissible Error J MPE:	$\pm 0.00065''$
Flatness:	0.00004"
Parallelism:	0.0004"
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
Measuring force:	10 - 15 N
Mass:	6940 g

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: 1,183.00 €*

Standard accessories:

Micrometer Setting Standard

Length: 33"

Art No. 167-173

Suggested retail price: 324.00 €*

