


## Outside Micrometer Economy Design

Item number: 103-216

### Images

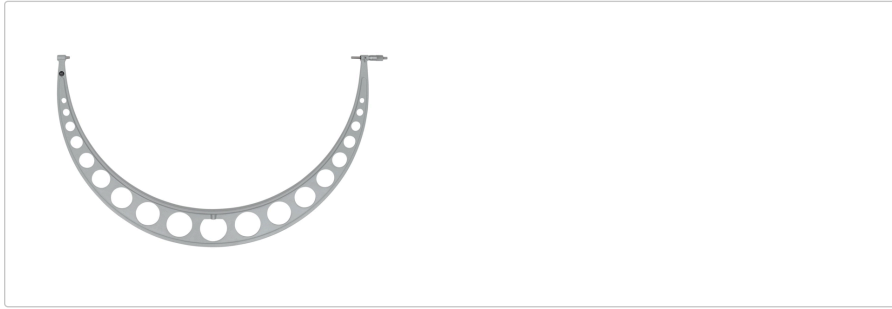

### Description

Lightweight workshop design with baked-enamel-finished frame.

- Equipped with Ratchet Stop for constant measuring force.

### Features

<b>Digital/Analog:</b>	Analog
<b>Delivered:</b>	Including box, key, setting standard
<b>Inch-Metric:</b>	Inch
<b>Range:</b>	39 - 40 "
<b>Graduation:</b>	0,001"
<b>Max. Permissible Error J MPE:</b>	$\pm 0.00075''$
<b>Flatness:</b>	0.00004"
<b>Parallelism:</b>	0.00048"
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring spindle:</b>	With spindle lock, $\varnothing 6,35$ mm ( $\leq 300$ mm) $\varnothing 8$ mm ( $> 300$ mm) , spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
<b>Measuring force:</b>	10 - 15 N
<b>Mass:</b>	8880 g

### Accessories

Optional accessories:



## Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: 1,183.00 €\*  

---

Standard accessories:

---

## Micrometer Setting Standard

Length: 39"

Art No. 167-179

Suggested retail price: 426.00 €\*  

---

