


Outside Micrometer Interchangeable Anvil

Item number: 104-135A

Images

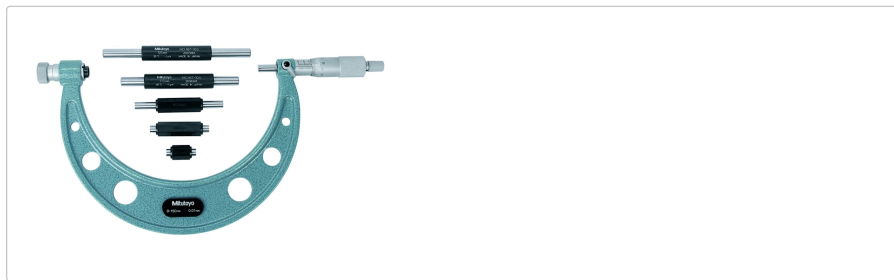


Description

A Mitutoyo non-digital micrometer provided with easily interchangeable anvils to enable a wide measuring range from one instrument. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	0 - 150 mm
Graduation:	0,01 mm
Limit of error:	$\pm 6 \mu\text{m}$
Delivered:	Including box, key, setting standard (5 pcs.), anvils (6 pcs.)
Spindle feed error:	$3 \mu\text{m}$
Flatness:	$0,6 \mu\text{m}$
Parallelism:	$3 \mu\text{m}$
Measuring face:	Carbide-tipped micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35 \text{ mm}$ ($\leq 300 \text{ mm}$) $\varnothing 8 \text{ mm}$ ($> 300 \text{ mm}$), spindle pitch $0,5 \text{ mm}$
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18 \text{ mm}$
Measuring force:	5 - 10 N
Setting standard:	5 (25, 50, 75, 100, 125 mm)
Interchangeable anvils:	6
Mass:	1.35 kg

Dimensions

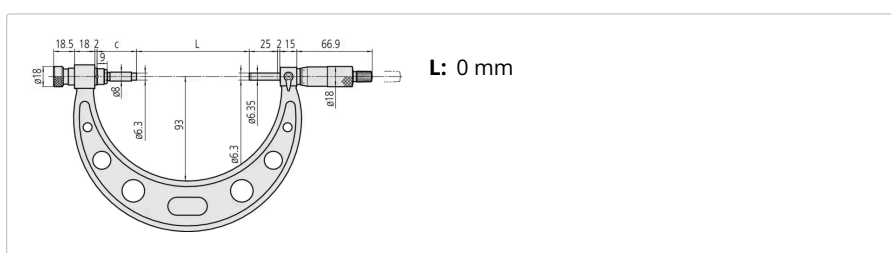

Accessories



Micrometer Setting Standard

Length: 25mm
Art No. 167-101
Suggested retail price: 33.00 €*



Micrometer Setting Standard

Length: 50mm
Art No. 167-102
Suggested retail price: 36.00 €*



Micrometer Setting Standard

Length: 75mm
Art No. 167-103
Suggested retail price: 37.00 €*



Micrometer Setting Standard

Length: 100mm
Art No. 167-104
Suggested retail price: 38.00 €*



Micrometer Setting Standard

Length: 125mm
Art No. 167-105
Suggested retail price: 41.00 €*
