


Outside Micrometer Interchangeable Anvil

Item number: 104-136A

Images

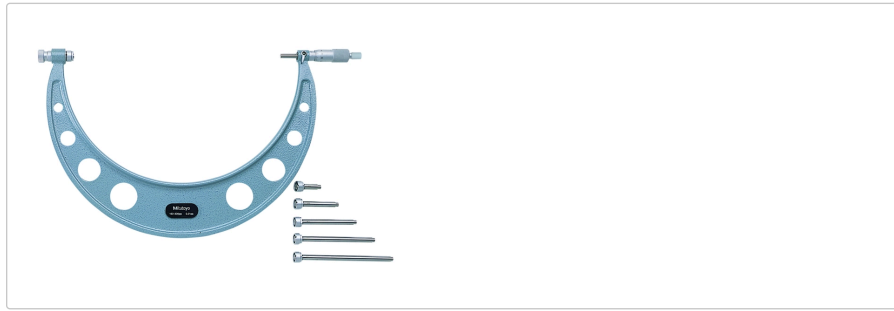


Description

A Mitutoyo non-digital micrometer provided with easily interchangeable anvils to enable a wide measuring range from one instrument. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	150 - 300 mm
Graduation:	0,01 mm
Limit of error:	$\pm 8 \mu\text{m}$
Delivered:	Including box, key, setting standard (6 pcs.), anvils (6 pcs.)
Spindle feed error:	$3 \mu\text{m}$
Flatness:	$0,6 \mu\text{m}$
Parallelism:	$5 \mu\text{m}$
Measuring face:	Carbide-tipped micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35 \text{ mm}$ ($\leq 300 \text{ mm}$) $\varnothing 8 \text{ mm}$ ($> 300 \text{ mm}$), spindle pitch $0,5 \text{ mm}$
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18 \text{ mm}$
Measuring force:	5 - 10 N
Setting standard:	6 (150, 175, 200, 225, 250, 275 mm)
Interchangeable anvils:	6
Mass:	2.65 kg


Dimensions

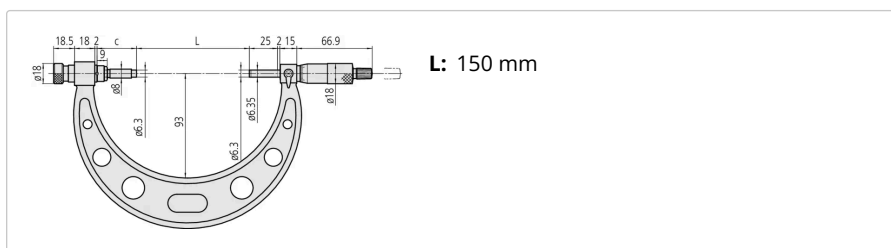

Standard accessories:

Micrometer Setting Standard

 Length: 150mm
Art No. 167-106
Suggested retail price: 43.00 €*



Micrometer Setting Standard

Length: 175mm
Art No. 167-107
Suggested retail price: 45.00 €*



Micrometer Setting Standard

Length: 200mm
Art No. 167-108
Suggested retail price: 50.00 €*



Micrometer Setting Standard

Length: 225mm
Art No. 167-109
Suggested retail price: 58.00 €*



Micrometer Setting Standard

Length: 250mm
Art No. 167-110
Suggested retail price: 62.00 €*



Micrometer Setting Standard

Length: 275mm

Art No. 167-111

Suggested retail price: 69.00 €*

