

Outside Micrometer Interchangeable Anvil

Item number: 104-137

Images




Description

A Mitutoyo non-digital micrometer provided with easily interchangeable anvils to enable a wide measuring range from one instrument. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0 - 6 "
Graduation:	0,001"
Limit of error:	±0,0003"
Delivered:	Including box, key, setting standard (5 pcs.), anvils (6 pcs.)
Spindle feed error:	0.00015 inch
Flatness:	0,000024"
Parallelism:	0.00012"
Measuring face:	Carbide-tipped micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Measuring force:	5 - 10 N
Setting standard:	5 (1, 2, 3, 4, 5")
Interchangeable anvils:	5
Mass:	1.35 kg

Dimensions

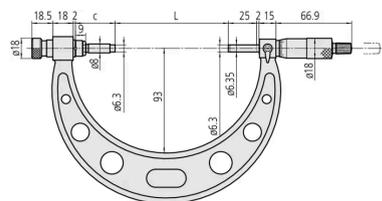

L: 0 mm

Accessories

Standard accessories:



Micrometer Setting Standard

Length: 1"

Art No. 167-141

Suggested retail price: 33.00 €*



Micrometer Setting Standard

Length: 2"

Art No. 167-142

Suggested retail price: 36.00 €*



Micrometer Setting Standard

Length: 3"

Art No. 167-143

Suggested retail price: 37.00 €*



Micrometer Setting Standard

Length: 4"

Art No. 167-144

Suggested retail price: 38.00 €*

Micrometer Setting Standard

Length: 5"

Art No. 167-145

Suggested retail price: 41.00 €*

