


Outside Micrometer Interchangeable Anvil

Item number: 104-138

Images

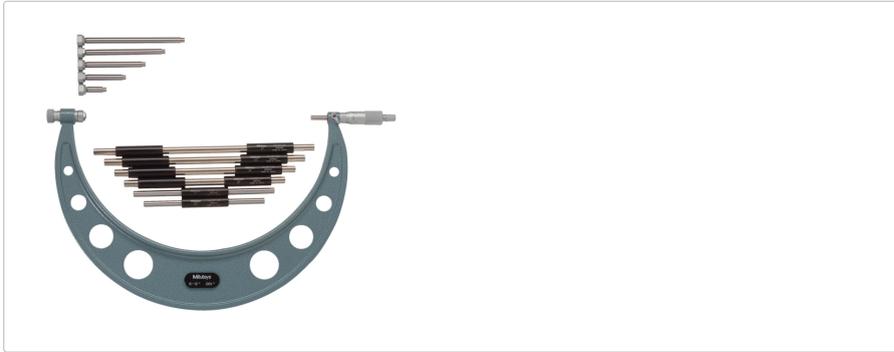


Description

A Mitutoyo non-digital micrometer provided with easily interchangeable anvils to enable a wide measuring range from one instrument. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	6 - 12 "
Graduation:	0,001"
Limit of error:	±0,0004"
Delivered:	Including box, key, setting standard (6 pcs.), anvils (6 pcs.)
Spindle feed error:	0.00015 inch
Flatness:	0,000024"
Parallelism:	0.0002"
Measuring face:	Carbide-tipped micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Measuring force:	5 - 10 N
Setting standard:	6 (6, 7, 8, 9, 10, 11")
Interchangeable anvils:	6
Mass:	2.65 kg

Dimensions

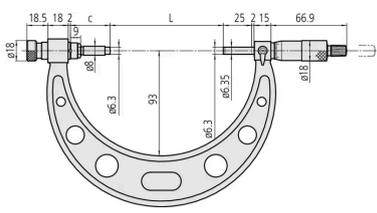

Accessories

Standard accessories:

Micrometer Setting Standard

Length: 6"

Art No. 167-146

Suggested retail price: 43.00 €*
*Suggested retail price is for reference only. Actual price may vary.



Micrometer Setting Standard

Length: 7"

Art No. 167-147

Suggested retail price: 45.00 €*
*Suggested retail price is for reference only. Actual price may vary.



Micrometer Setting Standard

Length: 8"

Art No. 167-148

Suggested retail price: 50.00 €*
*Suggested retail price is for reference only. Actual price may vary.



Micrometer Setting Standard

Length: 9"

Art No. 167-149

Suggested retail price: 58.00 €*
*Suggested retail price is for reference only. Actual price may vary.



Micrometer Setting Standard

Length: 10"

Art No. 167-150

Suggested retail price: 62.00 €*



Micrometer Setting Standard

Length: 11"

Art No. 167-151

Suggested retail price: 69.00 €*

