


Outside Micrometer Interchangeable Anvil

Item number: 104-144A

Images

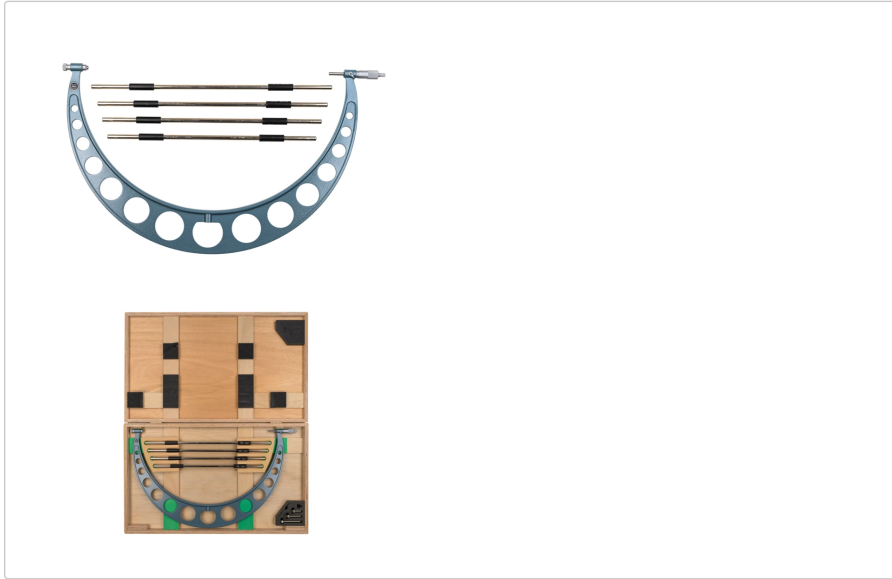


Description

A Mitutoyo non-digital micrometer that accepts easily interchangeable anvils to enable a wide variety of measurement, such as tubing thickness, shoulder-edge distance and rivet height. A friction thimble guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	500 - 600 mm
Graduation:	0,01 mm
Limit of error:	$\pm 12 \mu\text{m}$
Delivered:	Including box, key, setting standard (4 pcs.), anvils (4 pcs.)
Spindle feed error:	$3 \mu\text{m}$
Flatness:	$1 \mu\text{m}$
Parallelism:	$8 \mu\text{m}$
Measuring face:	Carbide-tipped micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35 \text{ mm}$ ($\leq 300 \text{ mm}$) $\varnothing 8 \text{ mm}$ ($> 300 \text{ mm}$), spindle pitch $0,5 \text{ mm}$
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21 \text{ mm}$
Measuring force:	10 - 14 N
Setting standard:	4 (500, 525, 550, 575 mm)
Interchangeable anvils:	4
Mass:	6.35 kg

Dimensions

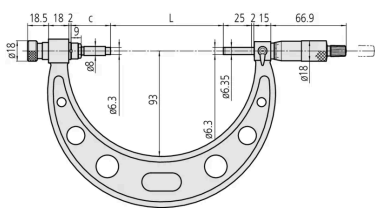

L: 500 mm

Accessories

Standard accessories:

Micrometer Setting Standard

Length: 500mm

Art No. 167-120

Suggested retail price: 159.00 €*


Micrometer Setting Standard

Length: 525mm

Art No. 167-121

Suggested retail price: 171.00 €*


Micrometer Setting Standard

Length: 550mm

Art No. 167-122

Suggested retail price: 176.00 €*


Micrometer Setting Standard

Length: 575mm

Art No. 167-123

Suggested retail price: 188.00 €*