


# Outside Micrometer Interchangeable Anvil

Item number: 104-149

## Images

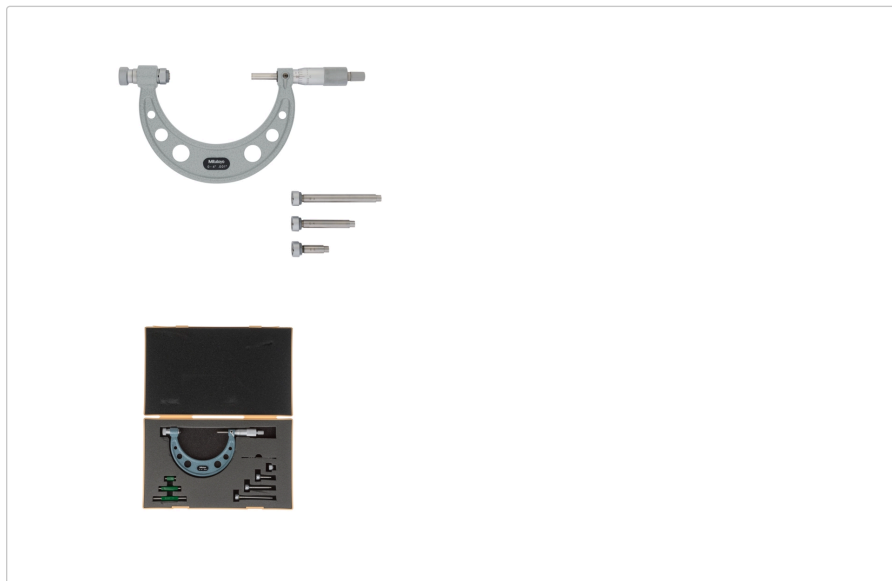


## Description

A Mitutoyo non-digital micrometer that accepts easily interchangeable anvils to enable a wide variety of measurement, such as tubing thickness, shoulder-edge distance and rivet height. A friction thimble guarantees repeatable measurement.

## Features

<b>Digital/Analog:</b>	Analog
<b>Delivered:</b>	Including box, key, setting standard (3 pcs.), anvils (4 pcs.)
<b>Inch-Metric:</b>	Inch
<b>Range:</b>	0 - 4 "
<b>Graduation:</b>	0,001"
<b>Limit of error:</b>	±0003"
<b>Spindle feed error:</b>	0.00015 inch
<b>Flatness:</b>	0.000024"
<b>Parallelism:</b>	0.00012"
<b>Measuring face:</b>	Carbide-tipped micro-lap finish spindle and hardened steel anvil
<b>Measuring spindle:</b>	With spindle lock, $\varnothing 6,35$ mm ( $\leq 300$ mm) $\varnothing 8$ mm ( $> 300$ mm) , spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
<b>Measuring force:</b>	5 - 10 N
<b>Setting standard:</b>	3 (1, 2, 3")
<b>Interchangeable anvils:</b>	3
<b>Mass:</b>	0.79 kg


## Dimensions

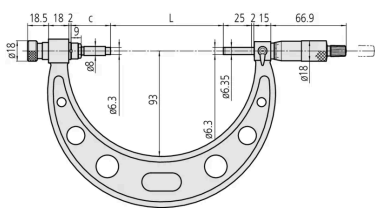

L: 0 mm

## Accessories

### Standard accessories:

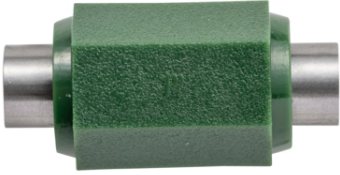

### Micrometer Setting Standard

Length: 1"

Art No. 167-141

Suggested retail price: 33.00 €\*



### Micrometer Setting Standard

Length: 2"

Art No. 167-142

Suggested retail price: 36.00 €\*



### Micrometer Setting Standard

Length: 3"

Art No. 167-143

Suggested retail price: 37.00 €\*