


## Outside Micrometer Interchangeable Anvil

Item number: 104-150

### Images

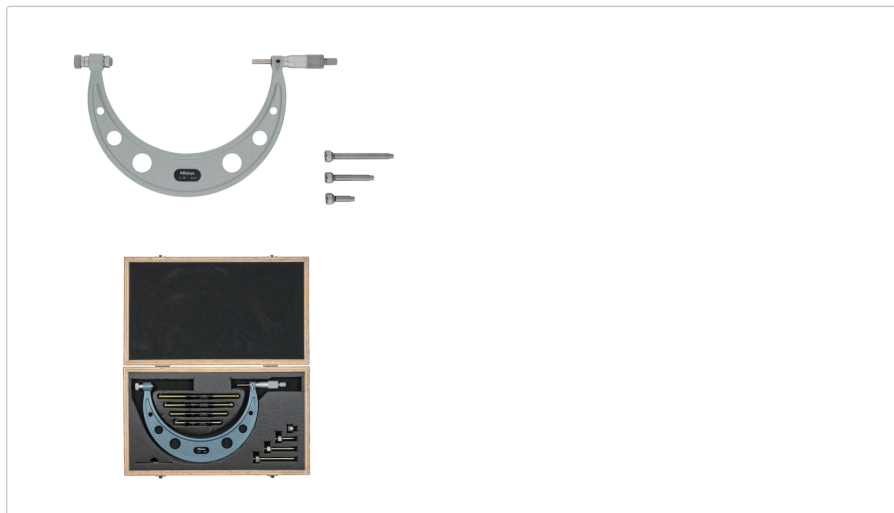


### Description

A Mitutoyo non-digital micrometer provided with easily interchangeable anvils to enable a wide measuring range from one instrument. A ratchet stop guarantees repeatable measurement.

### Features

<b>Digital/Analog:</b>	Analog
<b>Delivered:</b>	Including box, key, setting standard (4 pcs.), anvils (4 pcs.)
<b>Inch-Metric:</b>	Inch
<b>Range:</b>	4 - 8 "
<b>Graduation:</b>	0,001"
<b>Limit of error:</b>	±00035"
<b>Spindle feed error:</b>	0.00015 inch
<b>Flatness:</b>	0,000024"
<b>Parallelism:</b>	0,00016"
<b>Measuring face:</b>	Carbide-tipped micro-lap finish spindle and hardened steel anvil
<b>Measuring spindle:</b>	With spindle lock, $\varnothing 6,35$ mm ( $\leq 300$ mm) $\varnothing 8$ mm ( $> 300$ mm) , spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
<b>Measuring force:</b>	5 - 10 N
<b>Setting standard:</b>	4 (4, 5, 6, 7")
<b>Interchangeable anvils:</b>	4
<b>Mass:</b>	1.38 kg

### Dimensions

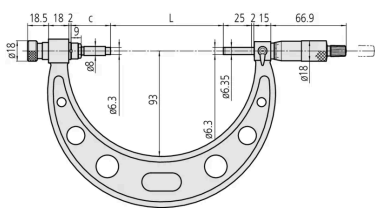

## Accessories

 
### Standard accessories:

#### Micrometer Setting Standard

Length: 4"

Art No. 167-144

Suggested retail price: 38.00 €\*



#### Micrometer Setting Standard

Length: 5"

Art No. 167-145

Suggested retail price: 41.00 €\*



#### Micrometer Setting Standard

Length: 6"

Art No. 167-146

Suggested retail price: 43.00 €\*



#### Micrometer Setting Standard

Length: 7"

Art No. 167-147

Suggested retail price: 45.00 €\*

