


Outside Micrometer Interchangeable Anvil

Item number: 104-155

Images

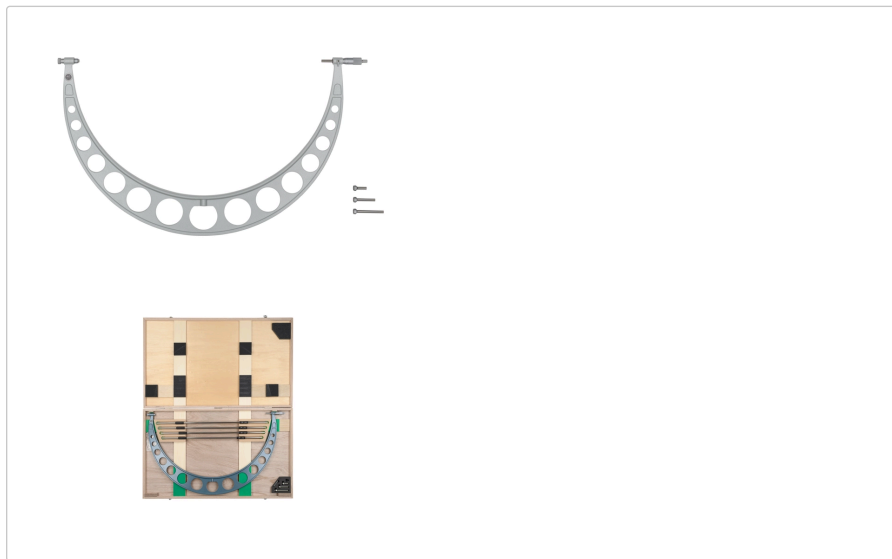


Description

A Mitutoyo non-digital micrometer provided with easily interchangeable anvils to enable a wide measuring range from one instrument. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Delivered:	Including box, key, setting standard (4 pcs.), anvils (4 pcs.)
Inch-Metric:	Inch
Range:	24 - 28 "
Graduation:	0,001"
Limit of error:	±0007"
Spindle feed error:	0.00015 inch
Flatness:	0,00004"
Parallelism:	0.00036"
Measuring face:	Carbide-tipped micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
Measuring force:	10 - 14 N
Setting standard:	4 (24, 25, 26, 27")
Interchangeable anvils:	4
Mass:	7.715 kg

Dimensions

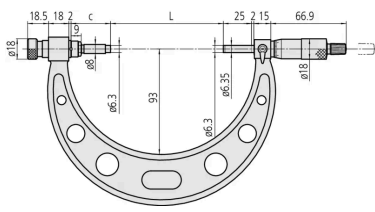

Accessories

Standard accessories:

Micrometer Setting Standard

Length: 24"

Art No. 167-164

Suggested retail price: 201.00 €*


Micrometer Setting Standard

Length: 25"

Art No. 167-165

Suggested retail price: 222.00 €*


Micrometer Setting Standard

Length: 26"

Art No. 167-166

Suggested retail price: 234.00 €*


Micrometer Setting Standard

Length: 27"

Art No. 167-167

Suggested retail price: 248.00 €*
