


# Outside Micrometer Interchangeable Anvil

Item number: 104-156

## Images

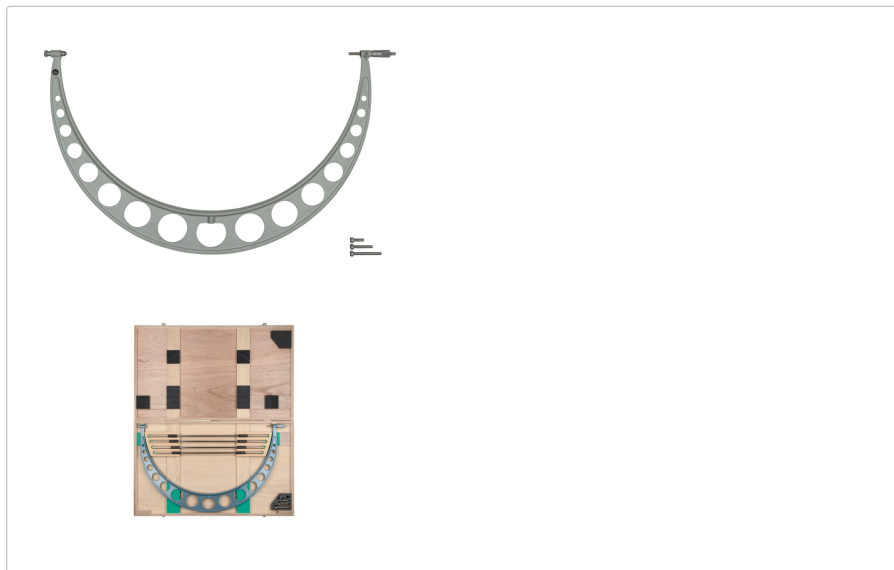


## Description

A Mitutoyo non-digital micrometer provided with easily interchangeable anvils to enable a wide measuring range from one instrument. A ratchet stop guarantees repeatable measurement.

## Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Inch
<b>Range:</b>	28 - 32 "
<b>Graduation:</b>	0,001"
<b>Limit of error:</b>	±00075"
<b>Delivered:</b>	Including box, key, setting standard (4 pcs.), anvils (4 pcs.)
<b>Spindle feed error:</b>	0.00015 inch
<b>Flatness:</b>	0,00004"
<b>Parallelism:</b>	0.0004"
<b>Measuring face:</b>	Carbide-tipped micro-lap finish spindle and hardened steel anvil
<b>Measuring spindle:</b>	With spindle lock, $\varnothing 6,35$ mm ( $\leq 300$ mm) $\varnothing 8$ mm ( $> 300$ mm) , spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
<b>Measuring force:</b>	10 - 14 N
<b>Setting standard:</b>	4 (28, 29, 30, 31")
<b>Interchangeable anvils:</b>	4
<b>Mass:</b>	9.075 kg

## Dimensions

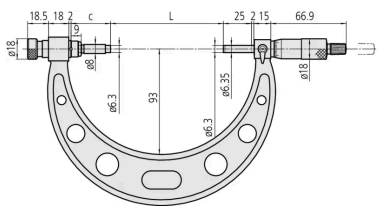

## Accessories

### Standard accessories:

#### Micrometer Setting Standard

Length: 28"

Art No. 167-168

Suggested retail price: 261.00 €\*  


#### Micrometer Setting Standard

Length: 29"

Art No. 167-169

Suggested retail price: 272.00 €\*  


#### Micrometer Setting Standard

Length: 30"

Art No. 167-170

Suggested retail price: 278.00 €\*  


#### Micrometer Setting Standard

Length: 31"

Art No. 167-171

Suggested retail price: 293.00 €\*  