

Outside Micrometer Interchangeable Anvil

Item number: 104-157

Images




Description

A Mitutoyo non-digital micrometer provided with easily interchangeable anvils to enable a wide measuring range from one instrument. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Delivered:	Including box, key, setting standard (4 pcs.), anvils (4 pcs.)
Inch-Metric:	Inch
Range:	32 - 36 "
Graduation:	0,001"
Limit of error:	±0008"
Spindle feed error:	0.00015 inch
Flatness:	0,00004"
Parallelism:	0.00044"
Measuring face:	Carbide-tipped micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
Measuring force:	10 - 14 N
Setting standard:	4 (32, 33, 34, 35")
Interchangeable anvils:	4
Mass:	10.405 kg

Dimensions

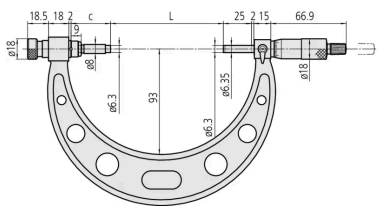

Accessories

Standard accessories:

Micrometer Setting Standard

Length: 32"

Art No. 167-172

Suggested retail price: 312.00 €*


Micrometer Setting Standard

Length: 33"

Art No. 167-173

Suggested retail price: 324.00 €*


Micrometer Setting Standard

Length: 34"

Art No. 167-174

Suggested retail price: 350.00 €*


Micrometer Setting Standard

Length: 35"

Art No. 167-175

Suggested retail price: 355.00 €*
