


Outside Micrometer Interchangeable Anvil

Item number: 104-165

Images

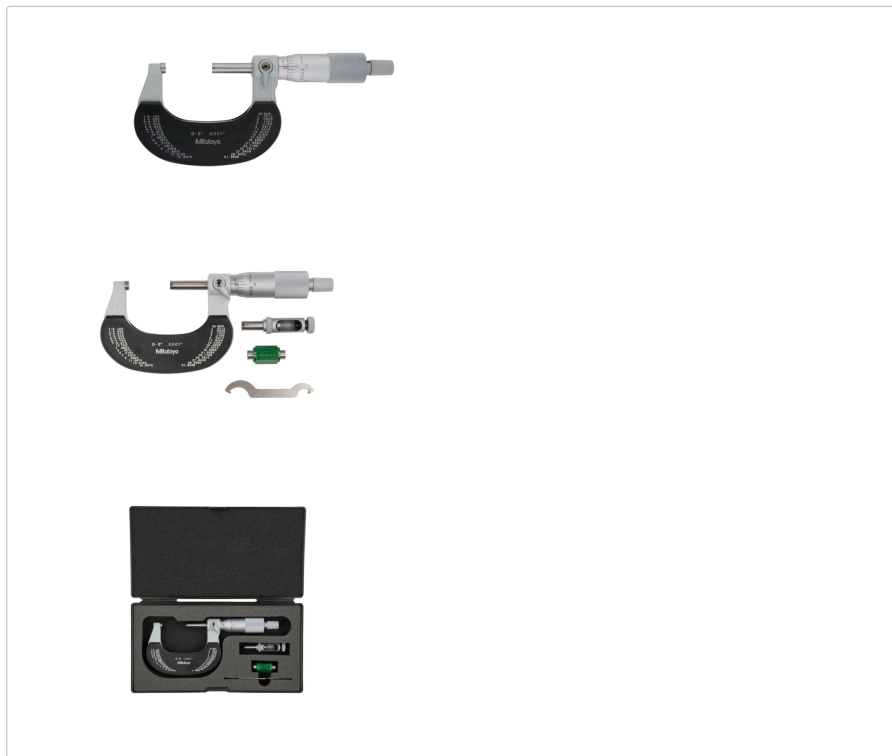

Description

This Outside Micrometer offers you an extra wide measuring range with the following benefits:

- Easy, interchangeable anvils allow a wide range of measurements.

Features


Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0 - 2 "
Graduation:	0.0001"
Limit of error:	±0,0002"
Delivered:	Including box, key, setting standard (1 pcs.), anvils (1 pcs.)
Spindle feed error:	0.00015 inch
Flatness:	0.000024"
Parallelism:	0.00008"
Measuring face:	Carbide-tipped micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Measuring force:	5 - 10 N
Setting standard:	1 (1")

Interchangeable anvils: 1

Mass: 0.32 kg

Accessories

Standard accessories:

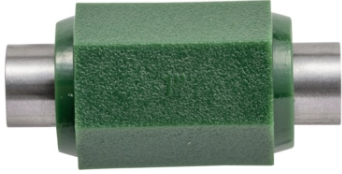

Micrometer Setting Standard

Length: 1"

Art No. 167-141

Suggested retail price: 33.00 €*