


Outside Micrometer Interchangeable Anvil

Item number: 104-201

Images

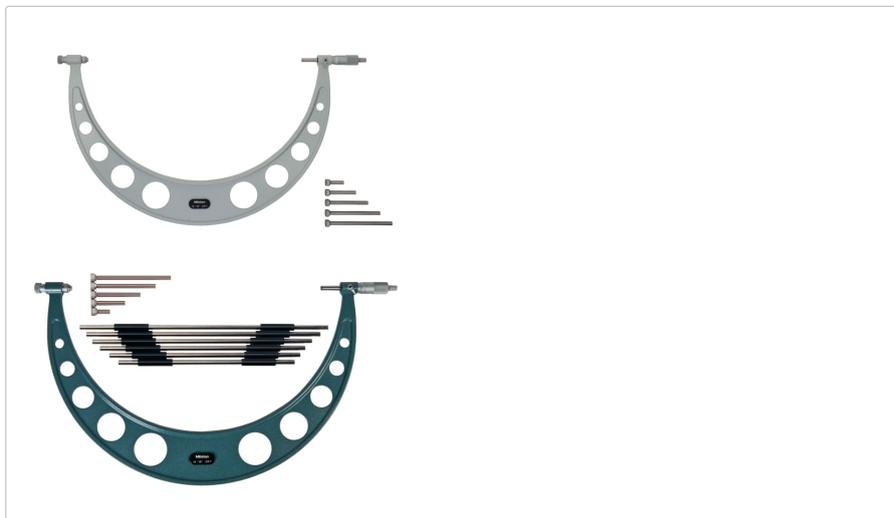


Description

A Mitutoyo non-digital micrometer provided with easily interchangeable anvils to enable a wide measuring range from one instrument. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	12 - 18 "
Graduation:	0,001"
Limit of error:	±0,0005"
Delivered:	Including box, key, setting standard (6 pcs.), anvils (6 pcs.)
Spindle feed error:	0.00015 inch
Flatness:	0,00004"
Parallelism:	0.00024"
Measuring face:	Carbide-tipped micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
Measuring force:	10 - 14 N
Setting standard:	6 (12, 13, 14, 15, 16, 17")
Interchangeable anvils:	6
Mass:	4.65 kg

Dimensions

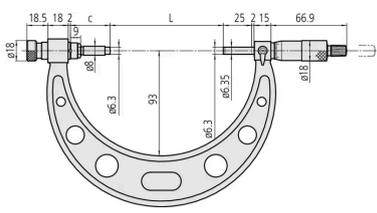

Accessories

Standard accessories:

Micrometer Setting Standard

Length: 12"

Art No. 167-152

Suggested retail price: 74.00 €*


Micrometer Setting Standard

Length: 13"

Art No. 167-153

Suggested retail price: 81.00 €*


Micrometer Setting Standard

Length: 14"

Art No. 167-154

Suggested retail price: 93.00 €*


Micrometer Setting Standard

Length: 15"

Art No. 167-155

Suggested retail price: 101.00 €*


Micrometer Setting Standard

Length: 16"

Art No. 167-156

Suggested retail price: 114.00 €*



Micrometer Setting Standard

Length: 17"

Art No. 167-157

Suggested retail price: 120.00 €*

