


Outside Micrometer Interchangeable Anvil

Item number: 104-202

Images

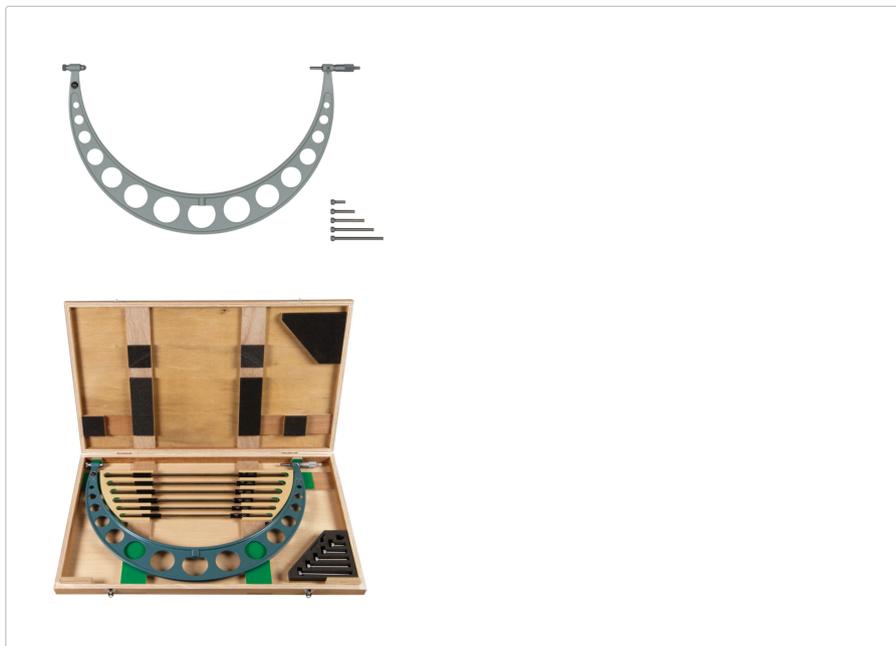

Description

A Mitutoyo non-digital micrometer provided with easily interchangeable anvils to enable a wide measuring range from one instrument. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	18 - 24 "
Graduation:	0,001"
Limit of error:	±0,0006"
Delivered:	Including box, key, setting standard (6 pcs.), anvils (6 pcs.)
Spindle feed error:	0.00015 inch
Flatness:	0,00004"
Parallelism:	0.00032"
Measuring face:	Carbide-tipped micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
Measuring force:	10 - 14 N
Setting standard:	6 (18, 19, 20, 21, 22, 23")
Interchangeable anvils:	6

Micrometer Setting Standard

Length: 22"

Art No. 167-162

Suggested retail price: 176.00 €*



Micrometer Setting Standard

Length: 23"

Art No. 167-163

Suggested retail price: 188.00 €*

