


Outside Micrometer Interchangeable Anvil

Item number: 104-203

Images

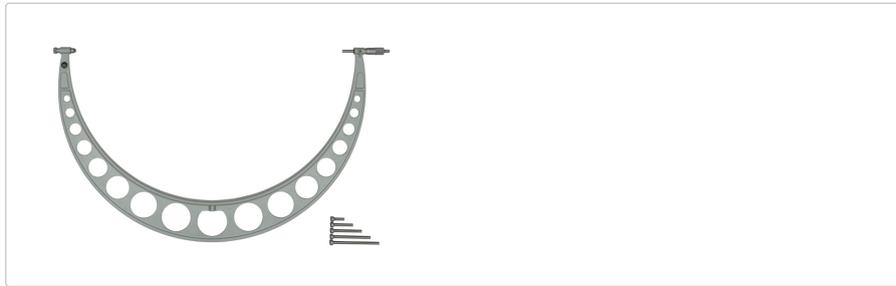


Description

A Mitutoyo non-digital micrometer provided with easily interchangeable anvils to enable a wide measuring range from one instrument. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	24 - 30 "
Graduation:	0,001"
Limit of error:	±0,0007"
Delivered:	Including box, key, setting standard (6 pcs.), anvils (6 pcs.)
Spindle feed error:	0.00015 inch
Flatness:	0,00004"
Parallelism:	0.00036"
Measuring face:	Carbide-tipped micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
Measuring force:	10 - 14 N
Setting standard:	6 (24, 25, 26, 27, 28, 29")
Interchangeable anvils:	6
Mass:	9.96 kg

Dimensions

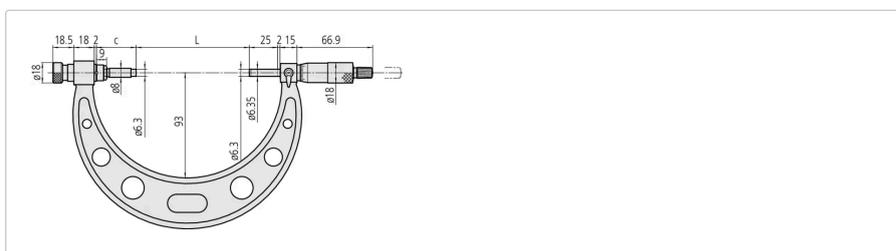

Standard accessories:

Micrometer Setting Standard

Length: 24"
Art No. 167-164
Suggested retail price: 201.00 €*


Micrometer Setting Standard

Length: 25"
Art No. 167-165
Suggested retail price: 222.00 €*


Micrometer Setting Standard

Length: 26"
Art No. 167-166
Suggested retail price: 234.00 €*


Micrometer Setting Standard

Length: 27"
Art No. 167-167
Suggested retail price: 248.00 €*


Micrometer Setting Standard

Length: 28"
Art No. 167-168
Suggested retail price: 261.00 €*


Micrometer Setting Standard

Length: 29"

Art No. 167-169

Suggested retail price: 272.00 €*

