
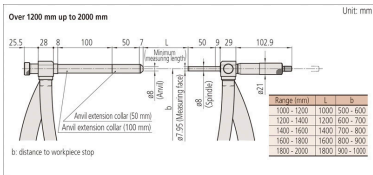
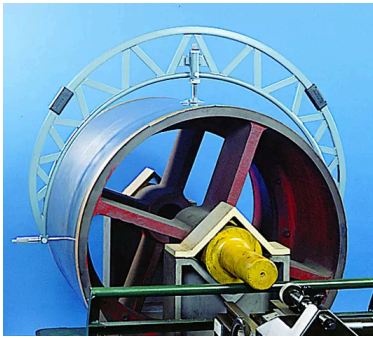


# Outside Microm. Anvil Extension Collar

Item number: 105-410

## Images

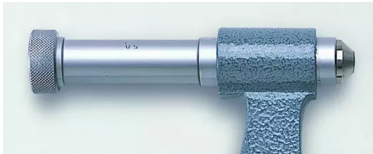

## Description

This Outside Micrometer comes with Extension Anvil Collars.

It offers you the following benefits:

 
- The collars have a stable and rugged yet lightweight tube construction, and are ideal for large micrometers.
- The 50 mm spindle stroke gives you extended range compared to standard spindle types.
- Anvil collars extend the measuring range even further.
- The setting standards supplied cover the whole measuring range.

## Features

<b>Model:</b>	OMS1-1300P
<b>Digital/Analog:</b>	Analog
<b>Delivered:</b>	Including box, with spanner, setting standard (2 pcs.), 50 mm extension collar
<b>Inch-Metric:</b>	Metric

<b>Measuring spindle:</b>	With spindle lock, ø8 mm, spindle pitch 0,5 mm
<b>Range:</b>	1,200 - 1,300 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, ø21 mm
<b>Graduation:</b>	0,01 mm
<b>Limit of error:</b>	±24 µm
<b>Spindle feed error:</b>	6 µm
<b>Flatness:</b>	1,3 µm
<b>Parallelism:</b>	15 µm
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring force:</b>	5-10 N
<b>Extension collar:</b>	50 mm
<b>Remarks:</b>	With workpiece stop 100 mm adjustable
<b>Mass:</b>	10.8 kg

### Dimensions



**L:** 1425 mm

**a:** 700 mm

### Accessories

Standard accessories:

#### Micrometer Setting Standard

Length: 1200mm

Art No. 167-372

Suggested retail price: 670.00 €\*



#### Micrometer Setting Standard

Length: 1250mm

Art No. 167-374

Suggested retail price: 709.00 €\*

