


Outside Microm. Anvil Extension Collar

Item number: 105-416

Images

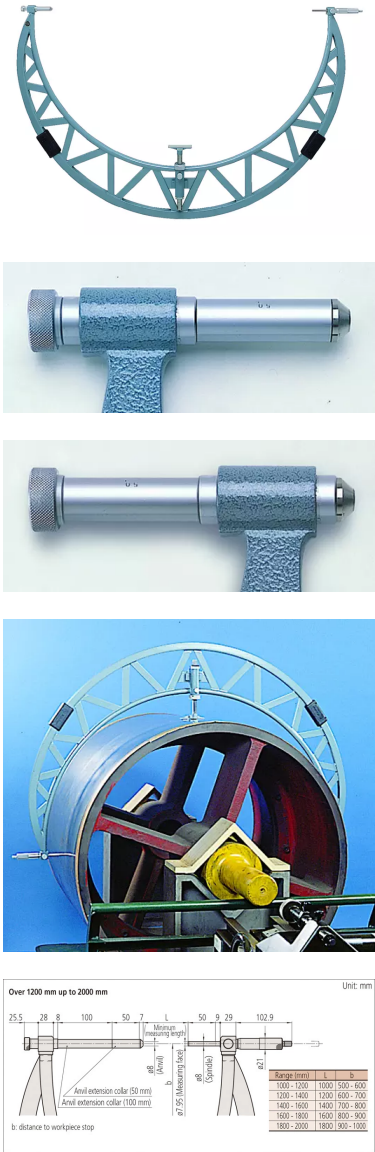

Description

This Outside Micrometer comes with Extension Anvil Collars. It offers you the following benefits:


- The collars have a stable and rugged yet lightweight tube construction, and are ideal for large micrometers.
- The 50 mm spindle stroke gives you extended range compared to standard spindle types.
- Anvil collars extend the measuring range even further.
- The setting standards supplied cover the whole measuring range.

Features

Model:	OMS1-1900P
Digital/Analog:	Analog
Delivered:	Including box, with spanner, setting standard (2 pcs.), 50 mm extension collar
Inch-Metric:	Metric

Measuring spindle:	With spindle lock, ø8 mm, spindle pitch 0,5 mm
Range:	1,800 - 1,900 mm
Scale:	Thimble and sleeve satin chrome finish, ø21 mm
Graduation:	0,01 mm
Limit of error:	±32 µm
Spindle feed error:	6 µm
Flatness:	1,3 µm
Parallelism:	21 µm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring force:	5-10 N
Extension collar:	50 mm
Remarks:	With workpiece stop 100 mm adjustable
Mass:	14.8 kg

 Dimensions



L: 2025 mm

a: 1000 mm

Accessories

Standard accessories:



Micrometer Setting Standard

Length: 1800mm

Art No. 167-396

Suggested retail price: **1,042.00 €***



Micrometer Setting Standard

Length: 1850mm

Art No. 167-398

Suggested retail price: **1,067.00 €***