 

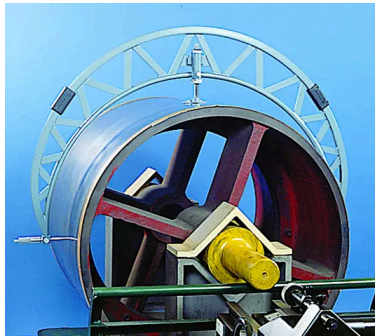


## Outside Microm. Anvil Extension Collar

Item number: 105-421

### Images

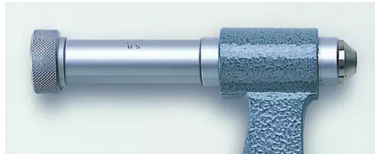

### Description

This Outside Micrometer comes with Extension Anvil Collars.

It offers you the following benefits:

- The collars have a stable and rugged yet lightweight tube construction, and are ideal for large micrometers.
- The 50 mm spindle stroke gives you extended range compared to standard spindle types.
- Anvil collars extend the measuring range even further.
- The setting standards supplied cover the whole measuring range.

### Features

<b>Model:</b>	OMS2-1800P
<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Metric
<b>Measuring spindle:</b>	With spindle lock, $\varnothing 8$ mm, spindle pitch 0,5 mm
<b>Range:</b>	1,600/1,800 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm

<b>Graduation:</b>	0,01 mm
<b>Limit of error:</b>	±30 µm
<b>Delivered:</b>	Including box, with spanner, setting standard (4 pcs.), 50/100 mm extension collar
<b>Spindle feed error:</b>	6 µm
<b>Flatness:</b>	1,3 µm
<b>Parallelism:</b>	20 µm
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring force:</b>	5-10 N
<b>Extension collar:</b>	50/100 mm
<b>Remarks:</b>	With workpiece stop 100 mm adjustable
<b>Mass:</b>	14.1 kg

## Dimensions

## Accessories

### Standard accessories:



### Micrometer Setting Standard

Length: 1600mm  
 Art No. 167-388  
 Suggested retail price: 926.00 €\*



### Micrometer Setting Standard

Length: 1650mm  
 Art No. 167-390  
 Suggested retail price: 952.00 €\*



### Micrometer Setting Standard

Length: 1700mm  
 Art No. 167-392  
 Suggested retail price: 991.00 €\*

## Micrometer Setting Standard

Length: 1750mm

Art No. 167-394

Suggested retail price: 1,017.00 €\*  

---

