


Outside Microm. Anvil Extension Collar

Item number: 105-433

Images

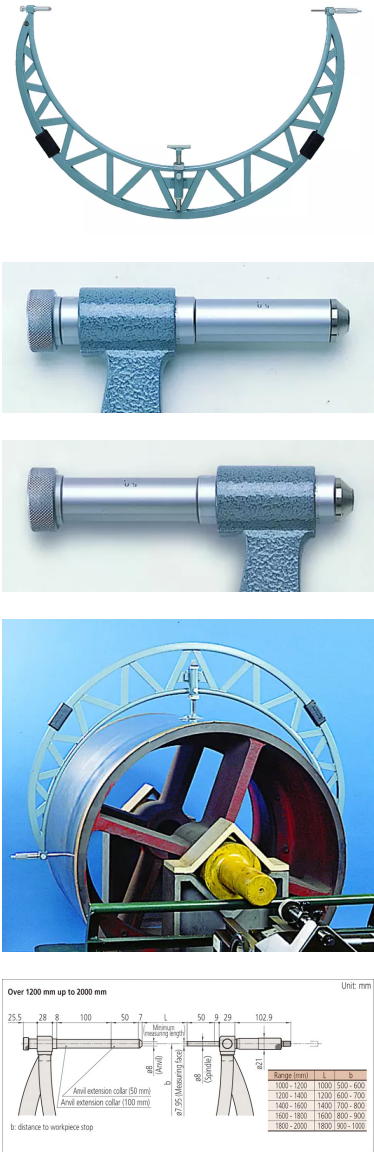

Description

This Outside Micrometer comes with Extension Anvil Collars. It offers you the following benefits:


- The collars have a stable and rugged yet lightweight tube construction, and are ideal for large micrometers.
- The 50 mm spindle stroke gives you extended range compared to standard spindle types.
- Anvil collars extend the measuring range even further.
- The setting standards supplied cover the whole measuring range.

Features

Digital/Analog:	Analog
Delivered:	Including box, with spanner, setting standard (2 pcs.), 2" extension collar
Inch-Metric:	Inch
Measuring spindle:	With spindle lock, ø8 mm, spindle pitch 0,5 mm

Range:	60 - 64 "
Scale:	Thimble and sleeve satin chrome finish, ø21 mm
Graduation:	0,001"
Limit of error:	±0,0014"
Spindle feed error:	0.0003 inch
Flatness:	0,000052"
Parallelism:	0.00071"
Measuring face:	Carbide-tipped, micro-lap finish
Measuring force:	5-10 N
Extension collar:	2"
Remarks:	With workpiece stop 100 mm adjustable
Mass:	13.2 kg

 Dimensions



L: 1625 mm

a: 800 mm

Accessories

Standard accessories:

Micrometer Setting Standard

Length: 60"
 Art No. 167-424
 Suggested retail price: 860.00 €*



Micrometer Setting Standard

Length: 62"
 Art No. 167-426
 Suggested retail price: 882.00 €*

