

Dial Gauge Micrometer

Item number: 107-201

Images



Description


This Dial Gauge Micrometer allows you to quickly measure mass-produced parts. It offers the following benefits:

- Designed to mount a dial or a Digital indicator for direct GO/NG judgement of mass-produced parts.
- You can take rapid measurements thanks to its anvil retracting trigger.
- 3 mm anvil retracting stroke.

Features

Inch-Metric:	Metric
Range:	0 - 25 mm
Graduation:	0.01 mm
Delivered:	Including box, with spanner
Anvil retracting stroke:	3 mm
Spindle feed error:	3 μ m
Flatness:	0,6 μ m
Parallelism:	2 μ m
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, \varnothing 6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish \varnothing 18 mm
Measuring force:	5 - 10 N
Mass:	480 g

Dimensions

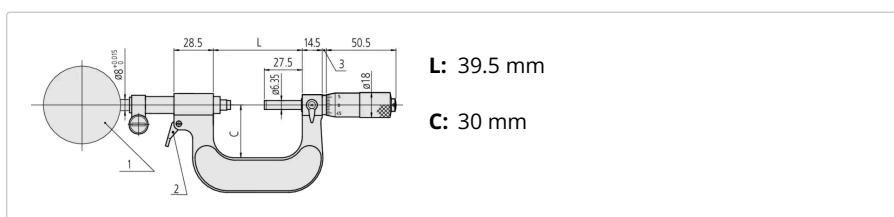

Accessories

Optional accessories:



Digital Indicator ID-C

12,7mm, 0,001mm, Flat Back
Art No. 543-390B
Suggested retail price: 344.00 €*
Suggested retail price: 344.00 €*
Suggested retail price: 344.00 €*



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
Art No. 156-105-10
Suggested retail price: 58.00 €*
Suggested retail price: 58.00 €*

Promotion!



Dial Gauge, Flat Back, ISO Type

10mm, 0,01mm
Art No. 2046AB
Promo price: **38.00 €***
Suggested retail price: ~~48.00 €*~~
Suggested retail price: 48.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10
Promo price: **56.00 €***
Suggested retail price: ~~70.00 €*~~
Suggested retail price: 70.00 €*



Digital Indicator ID-C

12,7mm, 0,01mm, Flat Back

Art No. 543-400B

Suggested retail price: 259.00 €*
Suggested retail price: 259.00 €*

Promotion!



Dial Gauge, Flat Back, ISO Type

Jewelled Bearing, Shockproof, 1mm,
0,001mm

Art No. 2109AB-10

Promo price: **84.00 €*
84.00 €***

Suggested retail price: ~~106.00 €*
106.00 €*~~