
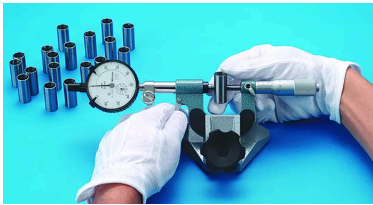


## Dial Gauge Micrometer

Item number: 107-207

### Images

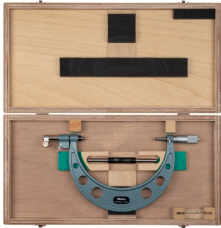

### Description

This Dial Gauge Micrometer allows you to quickly measure mass-produced parts. It offers the following benefits:

- Designed to mount a dial or a Digital indicator for direct GO/NG judgement of mass-produced parts.
- You can take rapid measurements thanks to its anvil retracting trigger.
- 3 mm anvil retracting stroke.

### Features

<b>Inch-Metric:</b>	Metric
<b>Range:</b>	150 - 175 mm
<b>Graduation:</b>	0.01 mm
<b>Delivered:</b>	Including box, with spanner, setting standard
<b>Anvil retracting stroke:</b>	3 mm
<b>Spindle feed error:</b>	3 $\mu$ m
<b>Flatness:</b>	0,6 $\mu$ m
<b>Parallelism:</b>	3 $\mu$ m
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring spindle:</b>	With spindle lock, $\varnothing$ 6,35 mm, spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish $\varnothing$ 18 mm
<b>Measuring force:</b>	5 - 10 N
<b>Mass:</b>	1050 g

Optional accessories:



**Digital Indicator ID-C**

12,7mm, 0,001mm, Flat Back  
Art No. 543-390B  
Suggested retail price: 344.00 €\*  
Suggested retail price: 344.00 €\*

Promotion!



**Dial Gauge, Flat Back, ISO Type**

10mm, 0,01mm  
Art No. 2046AB  
**Promo price: 38.00 €\*  
Suggested retail price: 48.00 €\*  
Suggested retail price: 48.00 €\***



**Digital Indicator ID-C**

12,7mm, 0,01mm, Flat Back  
Art No. 543-400B  
Suggested retail price: 259.00 €\*  
Suggested retail price: 259.00 €\*  
Suggested retail price: 259.00 €\*

Promotion!



## Dial Gauge, Flat Back, ISO Type

Jewelled Bearing, Shockproof, 1mm, 0,001mm

Art No. 2109AB-10

Promo price: **84.00 €\***

Suggested retail price: ~~106.00 €\*~~

Standard accessories:



## Micrometer Setting Standard

Length: 150mm

Art No. 167-106

Suggested retail price: 43.00 €\*