

## Contact Point Series 526

Item number: 10AAP247C

### Images



### Description

Split-ball probes 0,95-1,15 mm up to 6,7-7,3 mm range are protected by a diamond-like DLC coating.

Split-ball probes 7-18 mm are hard chrome plated


DLC Black Diamond:

- Extremely high wear protection, due to low frictional resistance
- Safety due to high hardness and resistance
- Safety due to sustained accuracy and precision

### Features

<b>Range:</b>	1.17 - 1.35 mm
<b>Marking on the measuring head (engraved):</b>	1.2
<b>Remarks:</b>	Fitting on 526-173-20, 526-172-20

### Dimensions

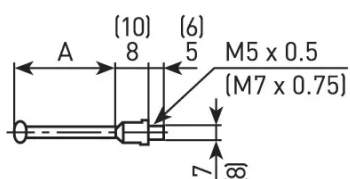

**A:** 11.5 mm

**Remarks:** ( ) 526-152-20, 526-153-20