


Micrometer Head, Differential Screw

Item number: 110-502-10

Images

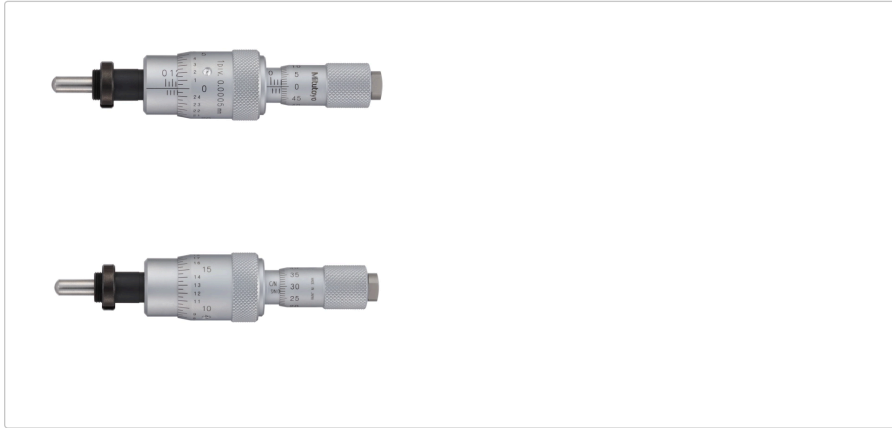

Description


This is a differential screw translator (extra-fine feed) type of micrometer head. It offers you the following benefits:

- Micrometer head with ultra-fine rate of travel.
- With its non-rotating spindle it is particularly suited to fine adjustments.
- The differential travel mechanism with double spindle enables ultra-sensitive travel

Features

Digital/Analog:	Analog
Delivered:	In a paper box with spanner 200154
Inch-Metric:	Metric
Range:	0 - 13 mm
Graduation:	A: 0,01 mm / B: 0,0005 mm
Maximum Permissible Error J MPE (Narrow):	$\pm 1,5 \mu\text{m}$
Max. Permissible Error J MPE:	$\pm 3 \mu\text{m} / \pm 1,5 \mu\text{m}$
Spindle end:	Spherical (SR3)
Stem \varnothing:	9.5 mm
Stem:	w/ clamp nut
Fixture thickness for clamp nut:	11.5 mm
Special features:	Range A: 0-13 mm, Range B: 0-0.2 mm
Measuring face:	Hardened steel (> 60 HRC)
Mass:	100 g

Dimensions

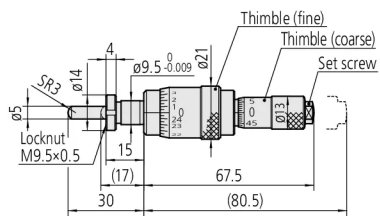

Accessories

Optional accessories:



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
 Art No. 303559
 Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
 Art No. 303568
 Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
 Art No. 303563
 Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
 Art No. 303572
 Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303561
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303570
Suggested retail price: 46.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303565
Suggested retail price: 43.00 €*



Fixture for Micrometer Head, Clamp Nut

for 9,5mm Stem
Art No. 303574
Suggested retail price: 46.00 €*
