

Spline Micrometer

Item number: 111-166

Images




Description

A Mitutoyo non-digital micrometer provided with a spindle and anvil reduced in diameter to enable measurement within slotted features, such as keyways. A ratchet stop guarantees repeatable measurement. High resolution provided by a vernier scale on sleeve.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0 - 1 "
Graduation:	0.0001"
Max. Permissible Error J MPE:	±0.00015"
Delivered:	Including box, spanner
Flatness:	0.000012"
Parallelism:	0.00008"
Measuring face:	Carbide-tipped, micro-lap finish, stepped
Anvil / Spindle:	Type A, D=3 mm
Measuring spindle:	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Measuring force:	5 - 10 N
Mass:	205 g

Dimensions

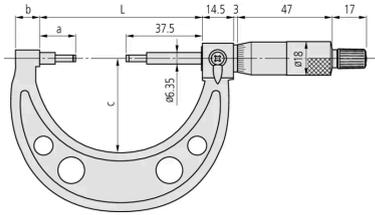


L: 55.3 mm

a: 17.8 mm

b: 10 mm

c: 38 mm

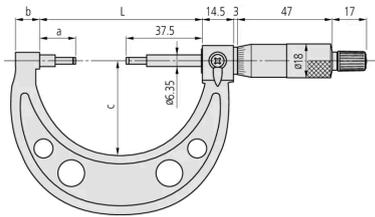


L: 55.3 mm

a: 17.8 mm

b: 10 mm

c: 38 mm

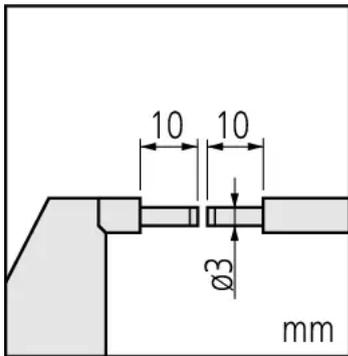

L: 55.3 mm

a: 17.8 mm

b: 10 mm

c: 38 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: 56.00 €*

Suggested retail price: 70.00 €*