

# Point Micrometer with Carbide Tip

Item number: 112-189

## Images




## Description

A Mitutoyo non-digital micrometer provided with pointed spindle and anvil to enable measurement within curved, slotted features, such as drilling-bit web thicknesses. A ratchet stop guarantees repeatable measurement.

## Features

|                                  |                                                                                    |
|----------------------------------|------------------------------------------------------------------------------------|
| Digital/Analog:                  | Analog                                                                             |
| Inch-Metric:                     | Inch                                                                               |
| Range:                           | 0 - 1 "                                                                            |
| Graduation:                      | 0,001"                                                                             |
| Max. Permissible Error<br>J MPE: | ±0.00015"                                                                          |
| Delivered:                       | Including box, spanner                                                             |
| Measuring face:                  | Carbide pointed or hardened steel spindle and anvil, measuring point radius 0.3 mm |
| Tip:                             | 15°                                                                                |
| Measuring spindle:               | With spindle lock, ø6,35 mm, spindle pitch 0,5 mm                                  |
| Scale:                           | Thimble and sleeve satin chrome finish, ø18 mm                                     |
| Measuring force:                 | 3 - 8 N                                                                            |
| Mass:                            | 205 g                                                                              |

## Dimensions

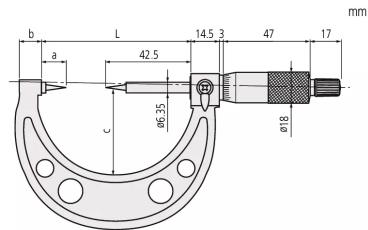


**L:** 55.3 mm

**a:** 12.8 mm

**b:** 10 mm

**c:** 38 mm

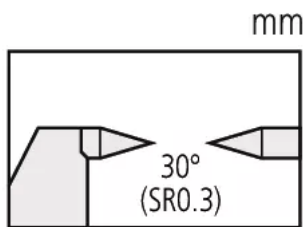

**L:** 55.3 mm

**a:** 12.8 mm

**b:** 10 mm

**c:** 38 mm

## Accessories

### Optional accessories:



### Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: **58.00 €\***



### Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €\***

~~Suggested retail price: 70.00 €±~~