

3 Flute V-Anvil Micrometer

Item number: 114-202

Images




Description

A Mitutoyo non-digital micrometer provided with a V-shaped anvil to enable measurement of 3-flute cutting tools, such as taps and reamers. A ratchet stop guarantees repeatable measurement. High resolution provided by a vernier scale on sleeve.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0,9 - 1 "
Graduation:	0.0001"
Max. Permissible Error J MPE:	±0.0002"
Delivered:	Including box, spanner, setting standard
Anvil:	Without groove
Measuring face:	Prism angle 60°/108°
Measuring spindle:	With spindle lock, ø6,35 mm, spindle pitch 0,75 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Measuring force:	5 - 10 N
Setting standard:	167-337 ø 0.2"
Mass:	290 g

Dimensions

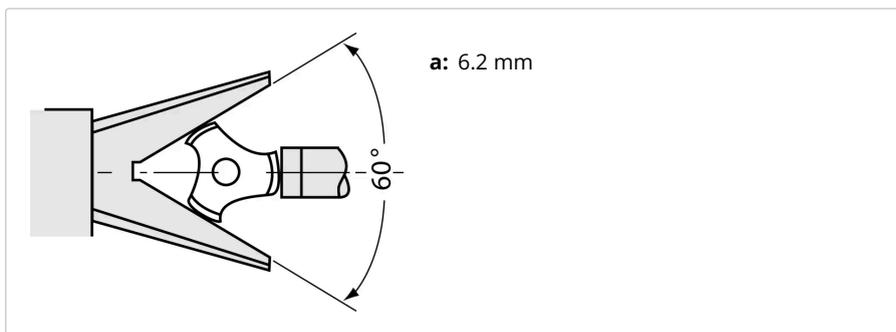

Accessories

Optional accessories:

