

Tube Micrometer, Spherical Anvil

Item number: 115-116

Images




Description

A Mitutoyo non-digital tube micrometer equipped with a spherical anvil for making wall thickness measurements on tubes and pipes. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	25 - 50 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	±3 µm
Delivered:	Including box, spanner, setting standard
Flatness:	0,6 µm
Measuring face:	Spindle and anvil: carbide-tipped, micro-lap finish (115-1xx, 115-2xx) spindle: carbide-tipped, micro-lap finish anvil: hardened steel (115-3xx)
Anvil / Spindle:	Type E, sperical anvil SR=4 mm/ flat spindle
Measuring spindle:	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Measuring force:	5 - 10 N
Mass:	240 g

Dimensions

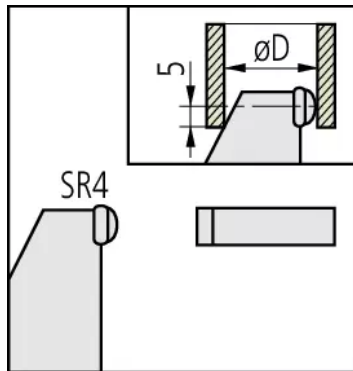

D: 11 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: 56.00 €*

Suggested retail price: 70.00 €*

Standard accessories:



Micrometer Setting Standard

Length: 25mm

Art No. 167-101

Suggested retail price: 33.00 €*