

Tube Micrometer, Spherical Anvil

Item number: 115-117

Images




Description

A Mitutoyo non-digital tube micrometer equipped with a spherical anvil for making wall thickness measurements on tubes and pipes. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	50 - 75 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	±3 µm
Delivered:	Including box, spanner, setting standard
Flatness:	0,6 µm
Measuring face:	Spindle and anvil: carbide-tipped, micro-lap finish (115-1xx, 115-2xx) spindle: carbide-tipped, micro-lap finish anvil: hardened steel (115-3xx)
Anvil / Spindle:	Type E, sperical anvil SR=4 mm/ flat spindle
Measuring spindle:	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Measuring force:	5 - 10 N
Mass:	315 g

Dimensions

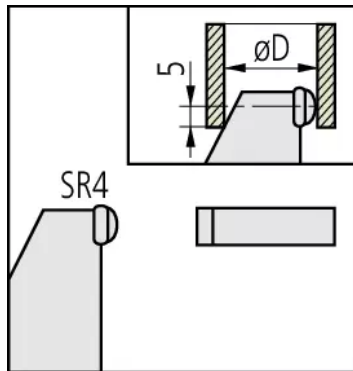

D: 17 mm

Accessories

Optional accessories:

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: ~~70.00 €*~~

Standard accessories:



Micrometer Setting Standard

Length: 50mm

Art No. 167-102

Suggested retail price: **36.00 €***