

Tube Micrometer, Spherical Anvil

Item number: 115-118

Images




Description

A Mitutoyo non-digital tube micrometer equipped with a spherical anvil for making wall thickness measurements on tubes and pipes. A ratchet stop guarantees repeatable measurement.

Features

| | |
|--------------------------------------|--|
| Digital/Analog: | Analog |
| Delivered: | Including box, spanner, setting standard |
| Inch-Metric: | Metric |
| Range: | 75 - 100 mm |
| Graduation: | 0,01 mm |
| Max. Permissible Error J MPE: | ±4 µm |
| Flatness: | 0,6 µm |
| Measuring face: | Spindle and anvil: carbide-tipped, micro-lap finish (115-1xx, 115-2xx) spindle: carbide-tipped, micro-lap finish anvil: hardened steel (115-3xx) |
| Anvil / Spindle: | Type E, spherical anvil SR=4 mm/ flat spindle |
| Measuring spindle: | With spindle lock, ø6,35 mm, spindle pitch 0,5 mm |
| Scale: | Thimble and sleeve satin chrome finish, ø18 mm |
| Measuring force: | 5 - 10 N |
| Mass: | 375 g |

Dimensions

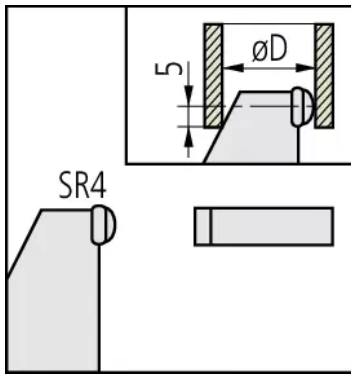

D: 18 mm

Accessories

Optional accessories:

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10
Promo price: **55.90 €***
Suggested retail price: ~~70.00 €*~~

Standard accessories:



Micrometer Setting Standard

Length: 75mm
Art No. 167-103
Suggested retail price: 37.00 €*