

# Tube Micrometer, Spherical Anvil

Item number: 115-153

## Images




## Description

A Mitutoyo non-digital tube micrometer equipped with a spherical anvil for making wall thickness measurements on tubes and pipes. A ratchet stop guarantees repeatable measurement.

## Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Inch
<b>Range:</b>	0 - 1 "
<b>Graduation:</b>	0,001"
<b>Max. Permissible Error J MPE:</b>	±0.00015"
<b>Delivered:</b>	Including box, spanner
<b>Flatness:</b>	0.000024"
<b>Measuring face:</b>	Spindle and anvil: carbide-tipped, micro-lap finish (115-1xx, 115-2xx) spindle: carbide-tipped, micro-lap finish anvil: hardened steel (115-3xx)
<b>Anvil / Spindle:</b>	Type E, spherical anvil SR=4 mm/ flat spindle
<b>Measuring spindle:</b>	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, ø18 mm
<b>Measuring force:</b>	5 - 10 N
<b>Mass:</b>	180 g

## Dimensions

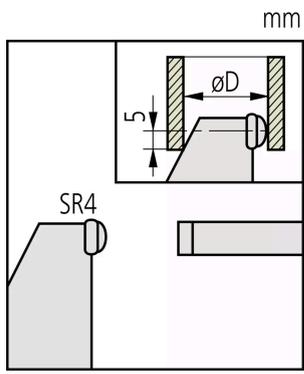

D: 10 mm

## Accessories

Optional accessories:



### Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"  
Art No. 156-105-10  
Suggested retail price: 58.00 €\*  
\*incl. VAT

Promotion!



### Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"  
Art No. 156-101-10  
Promo price: **56.00 €\*  
~~70.00 €\*  
\*incl. VAT~~**