

## Tube Micrometer

Item number: 115-309

### Images




### Description

This Tube Micrometer allows you to measure curved surfaces such as the wall thickness of tubes, bearings and rings.

### Features

<b>Digital/Analog:</b>	Analog
<b>Delivered:</b>	Including box, spanner, setting standard
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	25 - 50 mm
<b>Graduation:</b>	0,01 mm
<b>Max. Permissible Error J MPE:</b>	$\pm 3 \mu\text{m}$
<b>Flatness:</b>	0,6 $\mu\text{m}$
<b>Measuring face:</b>	Spindle and anvil: carbide-tipped, micro-lap finish (115-1xx, 115-2xx) spindle: carbide-tipped, micro-lap finish anvil: hardened steel (115-3xx)
<b>Anvil / Spindle:</b>	Type B, spherical pin D=3.5 mm/ flat spindle
<b>Measuring spindle:</b>	With spindle lock, $\varnothing 6,35$ mm, spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
<b>Measuring force:</b>	5 - 10 N
<b>Mass:</b>	240 g

### Dimensions

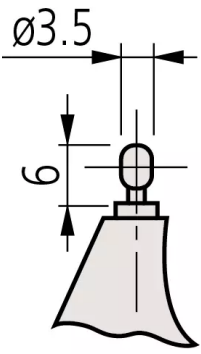

L: 4 mm

D: 3.6 mm



L: 4 mm

D: 3.6 mm

## Accessories

### Optional accessories:



### Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €\*

Promotion!



### Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **55.90 €\***

Suggested retail price: ~~70.00 €\*~~

### Standard accessories:



### Micrometer Setting Standard

Length: 25mm

Art No. 167-101

Suggested retail price: 33.00 €\*

