


## Tube Micrometer

Item number: 115-314

### Images

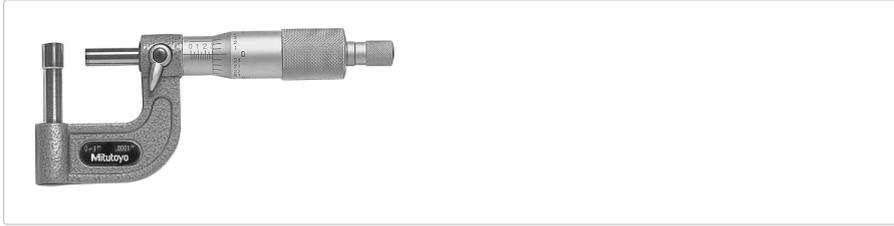

### Description

A Mitutoyo non-digital tube micrometer equipped with a cylindrical anvil on a post for making wall thickness measurements on tubes and pipes. A ratchet stop guarantees repeatable measurement.

### Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Inch
<b>Range:</b>	0 - 1 "
<b>Graduation:</b>	0,001"
<b>Max. Permissible Error J MPE:</b>	±0.00015"
<b>Delivered:</b>	Including box, spanner
<b>Flatness:</b>	0.000024"
<b>Measuring face:</b>	Spindle and anvil: carbide-tipped, micro-lap finish (115-1xx, 115-2xx) spindle: carbide-tipped, micro-lap finish anvil: hardened steel (115-3xx)
<b>Anvil / Spindle:</b>	Type D, cylindrical pin D=8 mm/ flat spindle
<b>Measuring spindle:</b>	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, ø18 mm
<b>Measuring force:</b>	3 - 8 N
<b>Mass:</b>	180 g

### Accessories

Optional accessories:

