


Interchangeable Anvil Micrometer

Item number: 117-107

Images

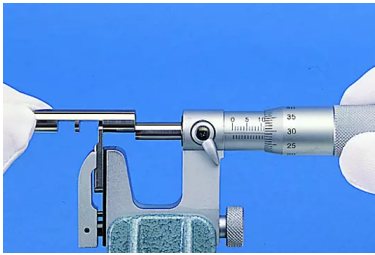

Description

A Mitutoyo non-digital micrometer that accepts easily interchangeable anvils to enable a wide variety of measurement, such as tubing thickness, shoulder-edge distance and rivet height. A friction thimble guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0 - 1 "
Graduation:	0.0001"
Delivered:	Including box, spanner, flat anvil 201216, rod anvil 201217
Spindle feed error:	0.00015 inch
Flatness:	0.000024" (spindle), 0.00008" (anvil)
Parallelism:	0.00012"
Measuring face:	Carbide-tipped micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm

V-Anvil

Art No. 201218

Suggested retail price: 30.00 €*



Standard accessories:

Flat Anvil

Art No. 201216

Suggested retail price: 37.00 €*



Cylindrical Anvil 3mm

Art No. 201217

Suggested retail price: 9.00 €*



Spare parts

Consumable spares:

Flat Anvil

Art No. 201216

Suggested retail price: 37.00 €*



Cylindrical Anvil 3mm

Art No. 201217

Suggested retail price: 9.00 €*



Cylindrical Anvil 5mm

Art No. 201379

Suggested retail price: 9.00 €*

