


## Disc Micrometer, Hardened Steel Disks

Item number: 123-101

### Images

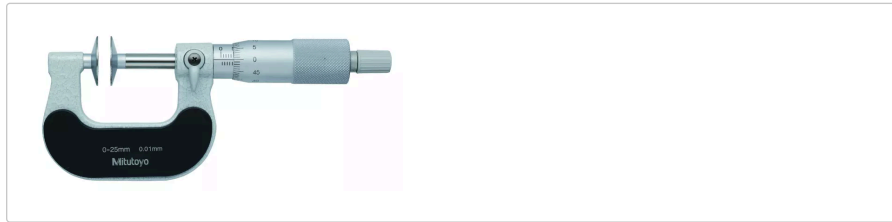


### Description

A Mitutoyo non-digital micrometer provided with disc-ended spindle and anvil to enable measurement of shrouded features, such as gear teeth. A ratchet stop guarantees repeatable measurement.

### Features

|                                      |                                                                                |
|--------------------------------------|--------------------------------------------------------------------------------|
| <b>Digital/Analog:</b>               | Analog                                                                         |
| <b>Inch-Metric:</b>                  | Metric                                                                         |
| <b>Range:</b>                        | 0 - 25 mm                                                                      |
| <b>Graduation:</b>                   | 0,01 mm                                                                        |
| <b>Max. Permissible Error J MPE:</b> | ±4 µm                                                                          |
| <b>Delivered:</b>                    | Including box, spanner                                                         |
| <b>Flatness:</b>                     | 1 µm                                                                           |
| <b>Parallelism:</b>                  | 4 µm                                                                           |
| <b>Measuring face:</b>               | Carbide-tipped (123-113, -114, -115, -116) or hardened steel spindle and anvil |
| <b>Measuring spindle:</b>            | With spindle lock, ø6,35 mm, spindle pitch 0,5 mm                              |
| <b>Scale:</b>                        | Thimble and sleeve satin chrome finish, ø18 mm                                 |
| <b>Measuring force:</b>              | 5 - 10 N                                                                       |
| <b>Measurable module:</b>            | 0.5 - 6 mm                                                                     |
| <b>Mass:</b>                         | 200 g                                                                          |

### Dimensions

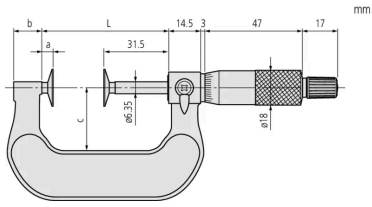


L: 37.5 mm

a: 6 mm

b: 14 mm

c: 25 mm

d: 20 mm

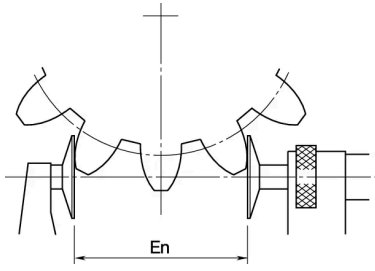

L: 37.5 mm

a: 6 mm

b: 14 mm

c: 25 mm

d: 20 mm



L: 37.5 mm

a: 6 mm

b: 14 mm

c: 25 mm

d: 20 mm

## Accessories

Optional accessories:



### Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €\*

Promotion!



### Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €\***

Suggested retail price: 70.00 €\*