

Screw Thread Micrometer

Item number: 125-102

Images



Description


This Screw Thread Micrometer has a fixed anvil, offering the following benefits:

- Fixed anvil type.
- It directly indicates screw pitch diameter, meaning no need for calculation.

Features

| | |
|--|--|
| Digital/Analog: | Analog |
| Inch-Metric: | Metric |
| Range: | 0 - 25 mm |
| Graduation: | 0,01 mm |
| Delivered: | Including box, spanner |
| Spindle feed error: | 3 μ m |
| Measuring face: | Hardened steel, fixed anvil/spindle |
| Measuring spindle: | With spindle lock, \varnothing 6,35 mm, spindle pitch 0,5 mm |
| Scale: | Thimble and sleeve satin chrome finish, \varnothing 18 mm |
| Thread to be measured (Metric/Unified): | 0,6-0,9 mm / 44-28 TPI |
| Tip angle: | 60° |
| Mass: | 200 g |

Dimensions

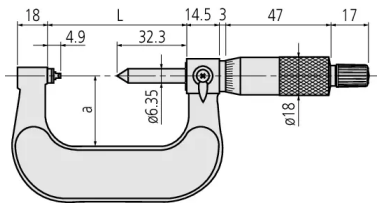

L: 37.2 mm

a: 25 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: 70.00 €*