


Screw Thread Micrometer

Item number: 125-104

Images

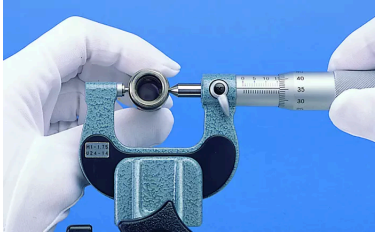

Description


This Screw Thread Micrometer has a fixed anvil, offering the following benefits:

- Fixed anvil type.
- It directly indicates screw pitch diameter, meaning no need for calculation.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	0 - 25 mm
Graduation:	0,01 mm
Delivered:	Including box, spanner
Spindle feed error:	3 μ m
Measuring face:	Hardened steel, fixed anvil/spindle
Measuring spindle:	With spindle lock, \varnothing 6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, \varnothing 18 mm
Thread to be measured (Metric/Unified):	2-3 mm / 13-9 TPI
Tip angle:	60°
Mass:	200 g

Dimensions

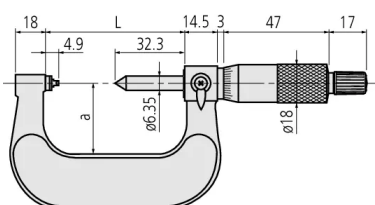

L: 37.2 mm

a: 25 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
Art No. 156-105-10
Suggested retail price: 58.00 €*
Suggested retail price: 58.00 €*
Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10
**Promo price: 56.00 €*
Suggested retail price: 70.00 €***