


Screw Thread Micrometer

Item number: 125-107

Images

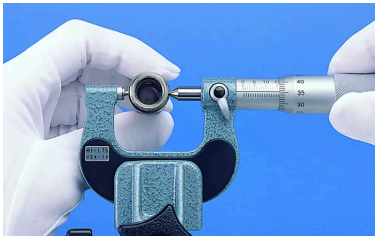

Description


This Screw Thread Micrometer has a fixed anvil, offering the following benefits:

- Fixed anvil type.
- It directly indicates screw pitch diameter, meaning no need for calculation.

Features

Digital/Analog:	Analog
Delivered:	Including box, spanner, setting standard 60°
Inch-Metric:	Metric
Range:	25 - 50 mm
Graduation:	0,01 mm
Spindle feed error:	3 μ m
Measuring face:	Hardened steel, fixed anvil/spindle
Measuring spindle:	With spindle lock, \varnothing 6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, \varnothing 18 mm
Thread to be measured (Metric/Unified):	0,6-0,9 mm / 44-28 TPI
Mass:	250 g

Dimensions

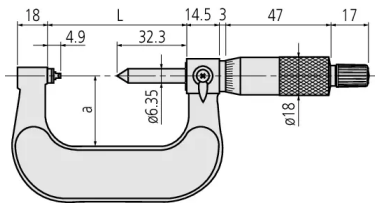

L: 62.2 mm

a: 32 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **55.90 €***

Suggested retail price: ~~70.00 €*~~

Standard accessories:



Setting Standard Screw Thread Micrometer

60°, Length: 25mm

Art No. 167-261

Suggested retail price: 68.00 €*